


Datasheet

Feed Through Terminals

RS Stock number 762-2521

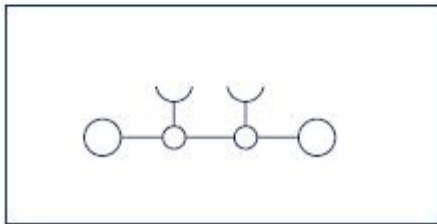

Feed-through terminal
2 connections

Features

- Foot can be snapped on TS 35 DIN rail
- Housing made from polyamide 6.6 UL 94-V0

Specifications:

Rated wire cross-section, mm² | AWG: 16 | 10-6

Rated impulse voltage, kV | Contamination degree: 8 | 3

Plug gauge acc. to EN 60 947-1 | Flamm. class acc. to UL 94: B7 | V2

Connection data

Single wire (solid) / Stranded mm²: 0.2-16 | 0.2-16

Stranded/stranded (w/ferrules acc. to DIN 46 228/1) mm²: 0.2-16 | 0.2-10

Contact wire range, mm²: 0.6-16

Stripping length, mm: 10

Torque, Nm | Screw: 2.0-4.0 | Slotted M 4