

Cord retaining strain relief screw-on mounting



C8  
  
70° C



### Description

- Screw-on from front side
- Protection against accidental disconnection of power supply cord

### References

Alternative: version for snap-in mounting [2578 retaining kit](#)

Component 1: Inlet [2576](#)

Component 2: [Retainer](#)

Component 3: Power cord with country specific line connector


### Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [Mating Connectors](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [CAD-Drawings](#), [Accessories](#), [Detailed request for product](#), [Video](#)

### Technical Data


|                      |                                                                    |
|----------------------|--------------------------------------------------------------------|
| Ratings IEC          | 2.5 A / 250 VAC; 50 Hz                                             |
| Ratings UL/CSA       | 7 A / 250 VAC; 60 Hz                                               |
| Degree of Protection | from front side IP 20 acc. to IEC 60529                            |
| Protection Class     | Suitable for appliances with protection class II acc. to IEC 61140 |

### Dimensions

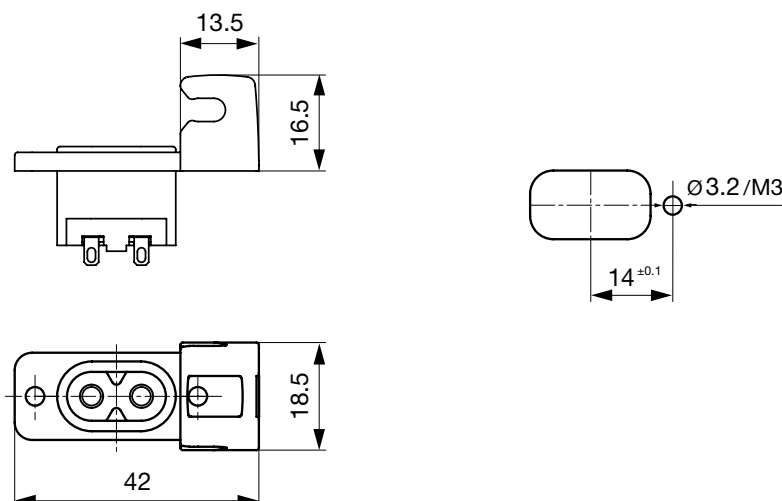

Retaining Kit

## Assembly Instructions

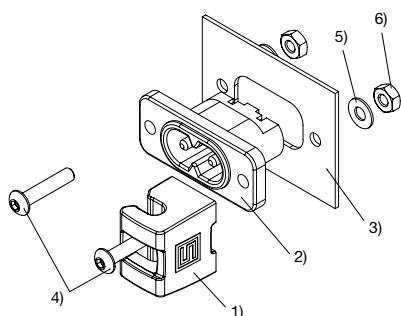

- 1) Retainer
- 2) Appliance Inlet
- 3) Panel
- 4) Screws (M3)
- 5) Washer
- 6) Nut (M3)

Screws, nuts and washers are not included in the kit

## Variants kit

| Description              | Appliance inlet | Cable     | Country | Length [m] | Retainer  | Order Number |   |
|--------------------------|-----------------|-----------|---------|------------|-----------|--------------|---|
| 2576 Retaining Kit US 2m | 6160.0021       | 6010.5274 | USA     | 2.0        | 0098.9273 | 6160.0108    | ■ |
| 2576 Retaining Kit US 4m | 6160.0021       | 6010.5278 | USA     | 4.0        | 0098.9273 | 6160.0109    | ■ |
| 2576 Retaining Kit EU 2m | 6160.0021       | 6013.0474 | EU      | 2.0        | 0098.9273 | 6160.0110    | ■ |
| 2576 Retaining Kit EU 4m | 6160.0021       | 6013.0478 | EU      | 4.0        | 0098.9273 | 6160.0111    | ■ |
| 2576 Retaining Kit US 2m | 6160.0058       | 6010.5274 | USA     | 2.0        | 0098.9273 | 6160.0112    | ■ |
| 2576 Retaining Kit US 4m | 6160.0058       | 6010.5278 | USA     | 4.0        | 0098.9273 | 6160.0113    | ■ |
| 2576 Retaining Kit EU 2m | 6160.0058       | 6013.0474 | EU      | 2.0        | 0098.9273 | 6160.0114    | ■ |
| 2576 Retaining Kit EU 4m | 6160.0058       | 6013.0478 | EU      | 4.0        | 0098.9273 | 6160.0115    | ■ |
| 2576 Retaining Kit US 2m | 6160.0022       | 6010.5274 | USA     | 2.0        | 0098.9273 | 6160.0116    | ■ |
| 2576 Retaining Kit US 4m | 6160.0022       | 6010.5278 | USA     | 4.0        | 0098.9273 | 6160.0117    | ■ |
| 2576 Retaining Kit EU 2m | 6160.0022       | 6013.0474 | EU      | 2.0        | 0098.9273 | 6160.0118    | ■ |
| 2576 Retaining Kit EU 4m | 6160.0022       | 6013.0478 | EU      | 4.0        | 0098.9273 | 6160.0119    | ■ |
| 2576 Retaining Kit US 2m | 6160.0028       | 6010.5274 | USA     | 2.0        | 0098.9273 | 6160.0120    | ■ |
| 2576 Retaining Kit US 4m | 6160.0028       | 6010.5278 | USA     | 4.0        | 0098.9273 | 6160.0121    | ■ |
| 2576 Retaining Kit EU 2m | 6160.0028       | 6013.0474 | EU      | 2.0        | 0098.9273 | 6160.0122    | ■ |
| 2576 Retaining Kit EU 4m | 6160.0028       | 6013.0478 | EU      | 4.0        | 0098.9273 | 6160.0123    | ■ |

Other appliance inlet on request

■ Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

**Packaging unit** 100 Pcs