


Self-aligning ball bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
20	52	21	14,3	4	0,21	-	9000	0,21	2304 E-2RS1TN9

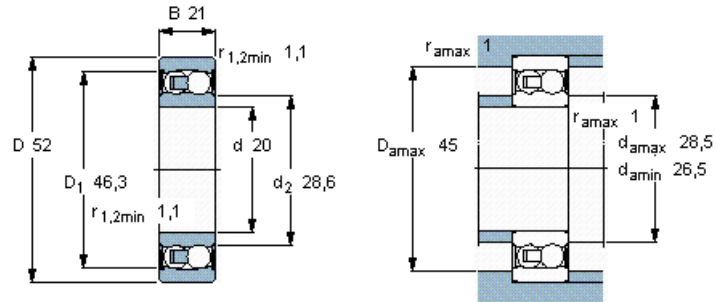

Calculation factors

- e 0,28
- Y_1 2,2
- Y_2 3,5
- Y_0 2,5