

Go To Step Search™ Screen

141085-2 -- 1 of 1 products


General **INFO**

Terminals and Splices

Sales **INFO**

FASTON Tabs, Tab Adapters, Tab Caps and Ultra-Fast Tabs

Customer Drawings **SPECIFICATIONS**

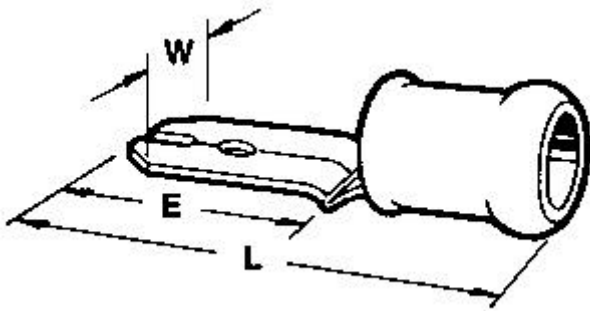

Line art represents typical product only.

Searchable Features:

Specials	None
Insulation	Fully Insulated
Tab Fit	.250 x .032 [6.35 x 0.81] in. [mm]
Mount	Wire Crimp
Material	Brass
Finish	Tin
Insulation Diameter	.224 [5.70] Max. in. [mm]
Packaging Method	Loose Piece
Wire/Cable Type	Regular Wire
Wire Range	[4.00-6.00 ²] AWG [mm]
Stud Size	None

Other Properties:

Tab Configuration	Regular
Dim. E	.370 [9.40] in. [mm]
Dim. L	1.102 [28.00] in. [mm]
Dim. W	.248 [6.30] in. [mm]
Color	Yellow
Insulation Sleeve Material	Nylon
CERTI-CRIMP Hand Tool	90276-2

[[Main Menu](#) | [Help](#) | [Families](#) | [Registration](#) | [Feedback](#)]
[Top of Page](#)