 


TRIO Series 3W LED Magnetic Square Light Kit



Magnetic Light: 70 x 70 x 11 mm
Driver: TRIO1212 ~ 127 x 49 x 13 mm

- Universal AC input / Full range
- Magnetic attachment allows fixing even to glass
- High lumen output
- 3 different finishes in 2 different styles
- Quick connect LED driver included
- Suitable for cabinets, decorative lighting and general task lighting; use it for display or show case lighting
- 120° Beam Angle




CE F M M IP44

Specification

Model Number	TRIO-3SW30K	TRIO-3SB30K	TRIO-3SS30K	TRIO-3SW60K	TRIO-3SB60K	TRIO-3SS60K
Fitting Colour	White	Black	Silver	White	Black	Silver
Input Current	330mA	330mA	330mA	330mA	330mA	330mA
Input Voltage	12V DC	12V DC	12V DC	12V DC	12V DC	12V DC
Power	3W x 3	3W x 3	3W x 3	3W x 3	3W x 3	3W x 3
Lumens	270lm	270lm	270lm	300lm	300lm	300lm
Colour	3000K	3000K	3000K	6000K	6000K	6000K
Lumen Field Angle	120°	120°	120°	120°	120°	120°
CRI	80	80	80	80	80	80
Weight	65g	65g	65g	65g	65g	65g
Dimensions	70x70x11mm	70x70x11mm	70x70x11mm	70x70x11mm	70x70x11mm	70x70x11mm

Mechanical Diagrams

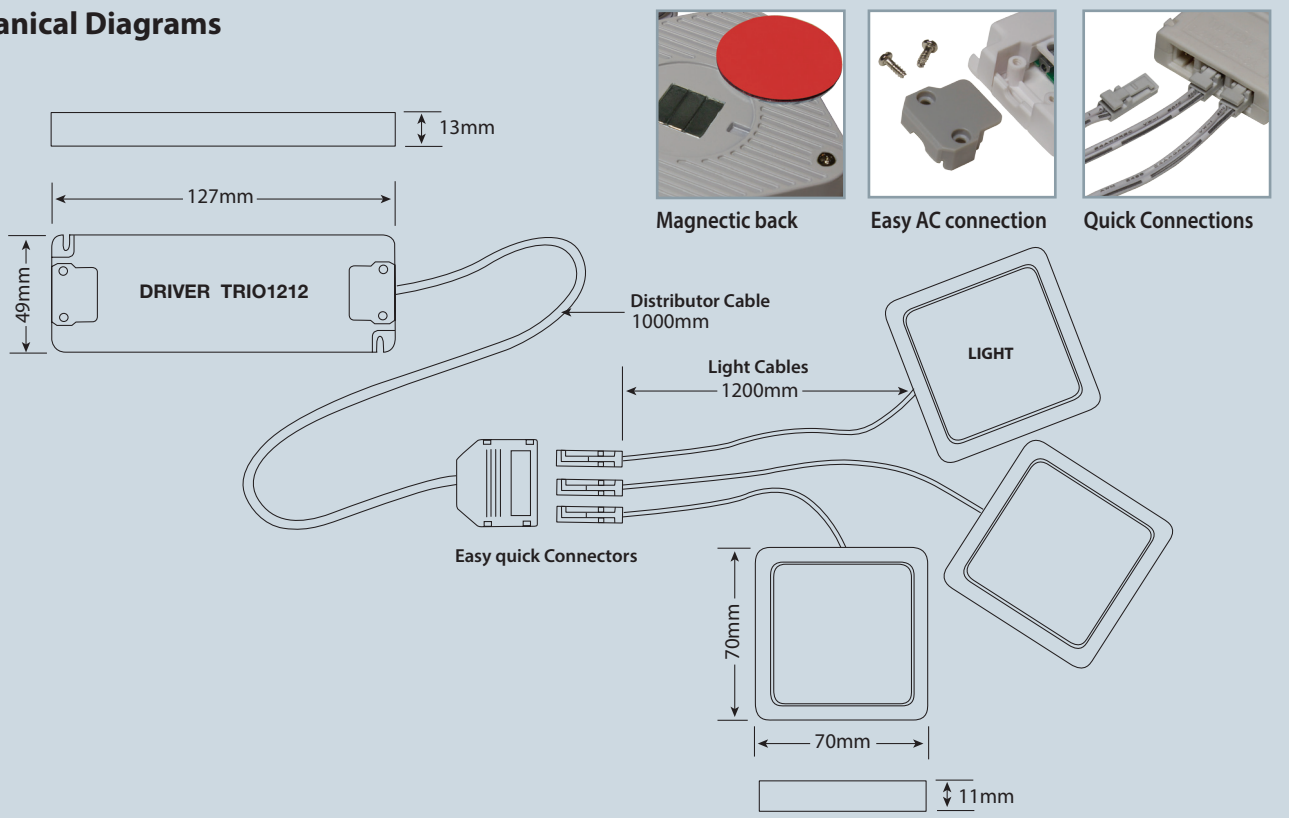

TRIO Series 3W LED Magnetic Round Light Kit



Magnetic Light: Ø 70 x 11 mm
Driver: TRIO1212 ~ 127 x 49 x 13 mm

- Universal AC input / Full range
- Magnetic attachment allows fixing even to glass
- High lumen output
- 3 different finishes in 2 different styles
- Quick connect LED driver included
- Suitable for cabinets, decorative lighting and general task lighting; use it for display or show case lighting
- 120° Beam Angle



CE F M M IP44

Specification

Model Number	TRIO-3RW30K	TRIO-3RB30K	TRIO-3RS30K	TRIO-3RW60K	TRIO-3RB60K	TRIO-3RS60K
Fitting Colour	White	Black	Silver	White	Black	Silver
Input Current	330mA	330mA	330mA	330mA	330mA	330mA
Input Voltage	12V DC	12V DC	12V DC	12V DC	12V DC	12V DC
Power	3W x 3	3W x 3	3W x 3	3W x 3	3W x 3	3W x 3
Lumens	270lm	270lm	270lm	300lm	300lm	300lm
Colour	3000K	3000K	3000K	6000K	6000K	6000K
Lumen Field Angle	120°	120°	120°	120°	120°	120°
CRI	80	80	80	80	80	80
Weight	65g	65g	65g	65g	65g	65g
Dimensions	Ø 70x11mm	Ø 70x11mm	Ø 70x11mm	Ø 70x11mm	Ø 70x11mm	Ø 70x11mm

Mechanical Diagrams

