


**65846-011LF - Mini-PV™, Basics+ : 2.54 x 2.54 mm (0.1 x 0.1 in.) Centerline Crimp-to-Wire PV Receptacle Housing, Double Row, Polarized**

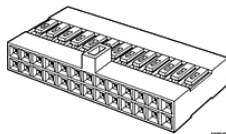

[www.fci.com](http://www.fci.com)

## Mating Half

- 69168-116HLF
- 78207-116HLF
- 67996-116HLF
- 68020-116HLF

## Specifications

<b>Approvals / Certifications</b>	
UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
<b>Dimensional</b>	
Length (Mating pin)	5.33 mm (0.21 in.) to 6.1 mm (0.24 in)
Size (Wire)	22 to 36 AWG
<b>Electrical</b>	
Resistance (Insulation)	100000 M-ohms
Voltage rating	1000V rms
<b>General</b>	
Number of contacts	16
Number of rows	2
Orientation	Vertical
Product Type	Crimp-to-Wire Housing
Polarization (Key)	Yes
Mating half	Mates with 0.64 mm (0.025 in.) Square Pin with Length of 5.33 mm (0.21 in.) min. to 6.1 mm (0.24 in.) max.
Series Number	65846
<b>Other Features</b>	
Accessory	Polarization Plug 65307-001LF
Packaging (Type)	Bag
Comments	PV™ Contact Removal Tool: Part Number HT-0080
<b>Physical</b>	
Color (Housing)	Black
Material (Housing)	PPE+PS
Temperature (Operating - range)	-40°C to +105°C