



CorePro LEDbulb

CorePro LEDBulb 5-32W E27 830

CorePro LEDbulbs are compatible with existing fixtures with an E27 or B22 holder and are designed for retrofit replacement of incandescent bulbs. They deliver huge energy savings and minimize maintenance cost.



PHILIPS

Product data

• General Characteristics

Cap-Base	E27
Bulb	A60 [A 60mm]
Rated Lifetime (hours)	15000 hr
Nominal Lifetime hours	15000 hr

• Light Technical Characteristics

Color Code	830
Color Designation (text)	White
Correlated Color Temperature	3000 K
Luminous Flux	350 Lm
Color rendering index	80
Luminous Efficacy Lamp	70.00 Lm/W
Color Temperature	3000 K [CCT 3000K]
Rated Luminous Flux	350 Lm
LLMF - end nominal lifetime	70 %
Colour consistency	6 steps

• Electrical Characteristics

Wattage	5 W
Wattage Technical	5 W
Voltage	220-240 V
Line Frequency	50-60 Hz
Power Factor	0.6 -
Lamp Current mA	44 mA
Dimmable	No
Wattage Equivalent	32 W
Rated Wattage	5.0 W

Starting Time	0.5 s
Suitable for accent lighting	No

• Temperature Characteristics

• Environmental characteristics

Energy Efficiency Label (EEL)	A+
-------------------------------	----

• Measuring Conditions

Switching cycle	50000X
-----------------	--------


• Product Dimensions

Overall Length C	102.6 mm
Diameter D	56.2 mm

• Product Data

Order code	929000248502
Full product code	929000248502
Full product name	CorePro LEDBulb 5-32W E27 830
Order product name	CorePro LEDBulb 5-32W E27 830
Pieces per pack	1
Packing configuration	6
Packs per outerbox	6
Bar code on pack - EAN1	8718291679332
Bar code on outerbox - EAN3	8718291679349
Logistic code(s) - 12NC	929000248502
Net weight per piece	0.074 kg

Photometric data

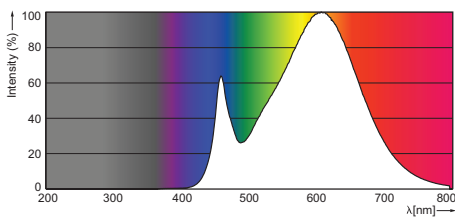

5-32W, 3000 K, 350 lm



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, August 3
data subject to change