


KEMET Part Number: MMK5154J63J01L15.0CBULK
 (F601JF154J063ALF0C, MMK5154J63J01L15,0CBULK)

MMK/F601, Film, Metallized Polyester, General Purpose, 0.15 uF, 5%, 63 VDC, 85°C, Lead Spacing = 5mm

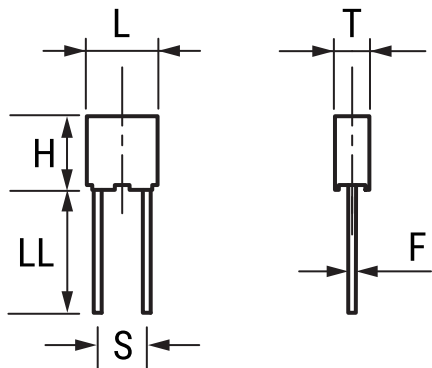

General Information	
Supplier:	KEMET
Series:	MMK/F601
Dielectric:	Metallized Polyester
Style:	Radial
Features:	DC Multipurpose Applications
RoHS:	Yes
Lead:	Wire Leads
Notes:	Not For New Design, Please Check Possible Alternative Parts (AltPart)

Dimensions	
L	7.2mm MAX
H	6.5mm MAX
T	2.5mm MAX
S	5mm +/-0.4mm
LL	15mm NOM
F	0.5mm NOM

Specifications	
Capacitance:	0.15 uF
Capacitance Tolerance:	5%
Voltage AC:	40 VAC
Voltage DC:	63 VDC, 48.8 VDC (100C)
Temperature Range:	-55/+100C
Rated Temperature:	85°C
Insulation Resistance:	15 GOhms
Max dV/dt:	25 V/us

Packaging Specifications	
Packaging:	Bulk, Bag