


Alnico Power magnet datasheet

- Alnico 5 magnet material
- Magnetically stable at high temperatures
- Max. operating temperature 220°C
- Mild steel pot
- Brass spacer
- Zinc plated body
- Diameter ground to H6 tolerance
- Custom designs available

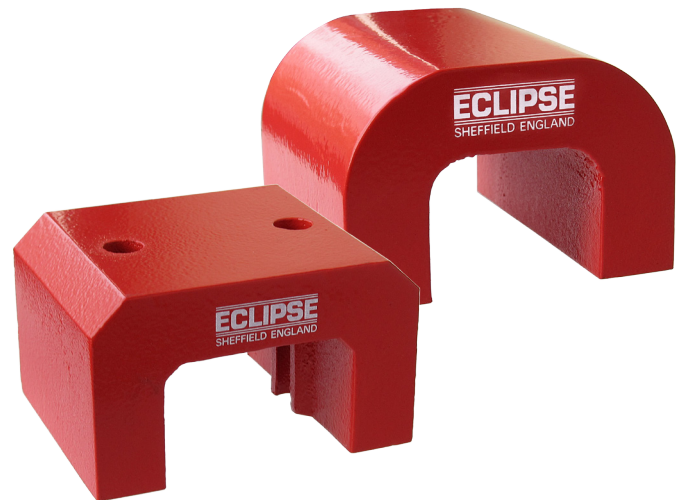

Product Information

Product No.	Length	Width	Height	Width of gap	Hole size	Hole centres	Weight	Pull force
			<i>mm</i>				<i>kg</i>	
811	30	20	20	15	5	n/a	0.060	4.5
812	40	25	25	20	5	n/a	0.120	9
813	45	30	30	23	5	n/a	0.180	11.8
814	57	44.5	35	27.8	2 × 7.9	31.75	0.370	23.5
815	70	57.2	41.3	34.1	2 × 7.9	38.10	0.710	37
816	79.4	82.6	54	38.1	2 × 9.5	42.86	1.450	47