


 


Indicator Lights Neon, LED and Filament Lamp

Colours and voltages:

-  **Neon** Available with Red, Amber, Green or Clear lenses
100/130V (marked 110V), 200/250V (marked 230V)
-  **LED - DC** Red, Yellow, Green, Blue, White
2.0/2.2V Resistors for other voltages available.
-  **LED - AC** Red, Yellow, Green, Blue, White
110-230V ac operation.
-  **Filament lamp** Available with Red, Amber, Green, Clear or Blue lenses
6V, 12/14V, 24/28V.

- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 6.7 to 16.3mm diameter
- ▶ Red, amber, green and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles








UL file E63363
CSA file 1317844 / 1279633 ①




 
 

 
 






 
 


 

 


 
 





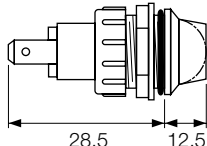

Approvals shown for neon versions only

RoHS RoHS compliant

To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

TERM	TYPE	PANEL & °C	ILLUMINATION OPTIONS	DIMENSIONS (mm)
L K 2.8 H 4.8 C 6.3	(C) 2870 00 	12.7 0.75-2.0 page 6	Neon LED-DC LED-AC Filament	9.9 22.8 5.0 Ø13.6
L K 2.8 H 4.8 C 6.3	(C) 0589 00 	12.7 0.8-1.5 page 6	Neon LED-DC Filament	10.5 21.6 3.2 Ø15.9
L	L 0081 00 Chrome bezel 	12.7 9.5 page 6	Neon LED-DC LED-AC Filament	Ø16.0 18.0 11.4 Ø18.3
L K 2.8 H 4.8 C 6.3	(C) 0177 00 Chrome bezel 	12.7 12.0max page 6	Neon LED-DC LED-AC Filament	14.9 22.2 3.3 8.3 53.7 32.2 Ø14.6
L K 2.8 H 4.8 C 6.3	(C) 0067 00 Chrome bezel 	12.7 1.14max page 6	Neon LED-DC LED-AC Filament	38.1 5.1 Ø16.0
L C 6.3	(C) 0180AA 	12.7 19.0max page 6	Neon LED-DC Filament	10.4 22.3 5.1 21.3 1.3 Starlock fixing

TERM	TYPE	PANEL & °C	ILLUMINATION OPTIONS	DIMENSIONS (mm)	
L  C 6.3 	(C) 0180BB Chrome bezel  	 13.5  0.9-1.14  page 6	  DC 	 10.4 22.3 5.1	 Ø16.3
L  K 2.8  H 4.8  C 6.3  C 6.3 	(C) 0579 00              	 14.0  2.5max  page 6	  DC  AC 	 10.0 25.4 3.2	 Ø15.9
C 6.3 	(C) 1092 	 19.0  4.0max  page 6	  AC	 28.5 12.5 max	 Ø22.9