



MINITEMP

Because there is more than one way
to measure temperature.

Raytek MiniTemp is pocket-sized and easy to use—just point, shoot and read the temperature on the large backlit display. When you need a fast, easy, safe way to measure surface temperature, you need a MiniTemp noncontact thermometer. Use MiniTemp at work, at home, anywhere.

Choice of Models




Choose between MiniTemp MT2, no laser sighting, or MiniTemp MT4, with laser sighting. Both models are powered by a 9V battery and display temperatures in either °C or °F. An accessory pack including a pouch and wrist strap is also available.

Applications

- AUTOMOTIVE—Troubleshoot engines including ignition system problems and fuel/air adjustments. Diagnose cooling systems including thermostats and coolant sensors; radiators; brakes; and tires.
- HVAC—Balance room temperatures, monitor supply/return registers, check furnace performance, perform energy audits, and check window insulation.
- ELECTRICAL—Check electrical panels for hot spots, find defective transformers, and detect loose electrical connections.
- FOOD SAFETY—Check holding, serving, and storage temperatures, maintain freezers, ovens, ranges, and dishwashers.
- AND MORE—Hundreds of work, home, and recreational applications.

FEATURES

Models	MT2	MT4
Emissivity	Pre-set to 0.95	Pre-set to 0.95
Laser (Class II)		√
Display hold (7 seconds)	√	√
LCD backlight	√	√
Temperature display	°C or °F selectable	
D:S (distance to spot size) (at nominal 90% energy)	6:1	6:1

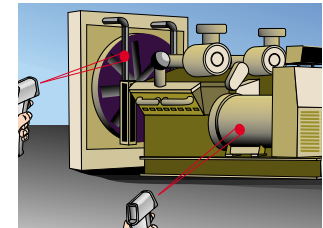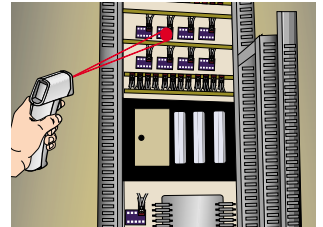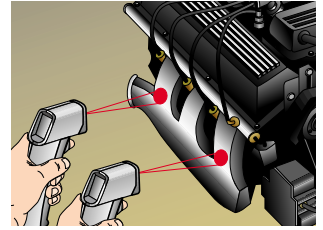


SPECIFICATIONS


Temperature Range	-18 to 260°C (0 to 500°F)
Accuracy	(assumes ambient operating temperature of 23°C [73°F]) For targets at -1 to 260°C (30 to 500°F), ±2% of reading or ±2°C (±3.5°F), whichever is greater; For targets at -18 to -1°C (0 to 30°F), ±3°C (±5°F)
Repeatability	±2% of reading or ±2°C (±3°F), whichever is greater
Response Time	500 mSec, 95% response
Ambient Operating Range	0 to 50°C (32 to 120°F)
Power	9V Alkaline or NiCd battery
Dimensions	152 x 101 x 38 mm (6 x 4 x 1.5 in)
Weight	227 g (0.5 lb)

OPTIONS / ACCESSORIES

Soft Pouch with Wrist Strap

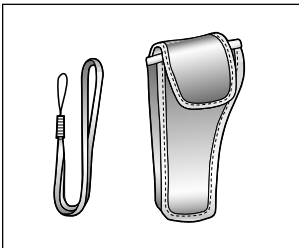

Target Spot Sizes

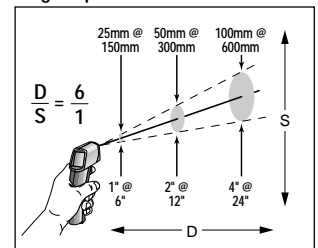

D:S = 6:1 at focal point



© 1999 Raytek Corporation, Printed in the USA, 0499MTBRO1 Rev B
Raytek, and the Raytek logo are registered trademarks and MiniTemp is a trademark of Raytek Corporation. Specifications are subject to change without notice. Y2K Compliant.

Distributed by:



Worldwide Headquarters
Raytek Corporation
 Santa Cruz, CA USA
 Tel: 1 800 866 5478
 831 458 1110
 Fax: 1 831 425 4561
 www.raytek.com



European Headquarters
Raytek GmbH
 Berlin, Germany
 Tel: 49 30 4 78 00 80
 Fax: 49 30 4 71 02 51

South American Headquarters
Raytek do Brasil
 Sorocaba, Brazil
 Tel: 55 15 233 6338
 Fax: 55 15 233 6826

Raytek China Company
 Beijing, China
 Tel: 86 10 6437 0284
 Fax: 86 10 6437 0285

Raytek France
 Palaiseau, France
 Tel: 33 1 64 53 1540
 Fax: 33 1 64 53 1544

Raytek Japan, Inc.
 Tokyo, Japan
 Tel: 81 3 3822 5715
 Fax: 81 3 3822 5712

Raytek de Mexico SA de C.V.
 Puebla, Mexico
 Tel: 52 22 30 4380
 Fax: 52 22 30 4438

Raytek U.K.
 Milton Keynes, UK
 Tel: 44 1908 630800
 Fax: 44 1908 630900