




Datasheet

Stock No: 241-4912

ENGLISH

RS Pro Nylon 66 Saddle Clip, 9.1 x 4 x 12.09mm

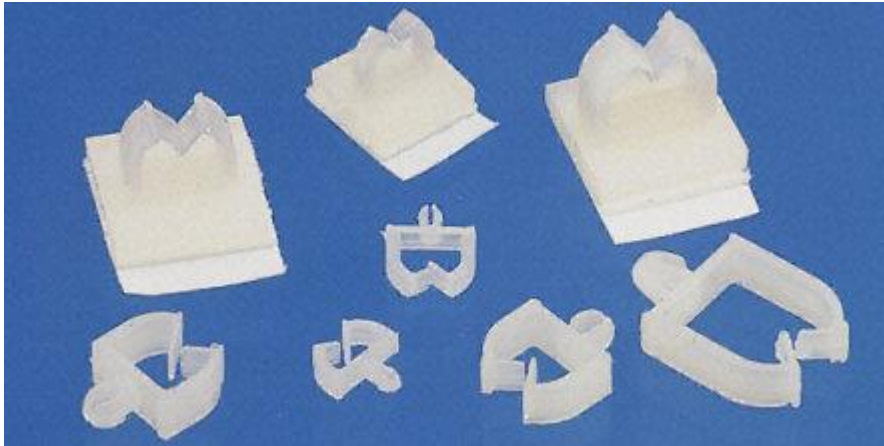

Product Details:

Micro Wire Saddles


- Micro wire saddles with sprung top loading for use where space is at a premium
- Two mounting base styles - teardrop (type T) for easy insertion and barbed (type A) for high strength locking
- Short projection below panel

Specifications:

| | |
|-------------------------|-------------|
| Cable Clip/Clamp Style: | Saddle Clip |
| Affixing Method: | Snap In |
| Material: | Nylon 66 |
| Colour: | Natural |
| Length: | 9.1mm |
| Width: | 4 mm |
| Depth: | 12.09mm |

| Dimensions (mm) | | | | | | | | |
|-----------------|-----------|----------|-----------------|------------|-----|------|-----|-----|
| Type | Stock No. | Hole Dia | Panel Thickness | Dimensions | | | | |
| Press Stud Base | | | | A | B | C | D | E |
| T | 241-4906 | 3 | 1.0/1.2 | 7.3 | 4.3 | 3.6 | 2.9 | 9.1 |
| A | 241-4855 | 3 | 1.6 | 7.3 | 5 | 4.25 | 3.1 | 9.1 |
| A | 241-4861 | 3.5 | 1.6 | 7.3 | 5 | 4.25 | 3.1 | 9.1 |
| A | 241-4899 | 3.5 | 1.6 | 13 | 5 | 4.25 | 3.1 | 12 |

スナップ式

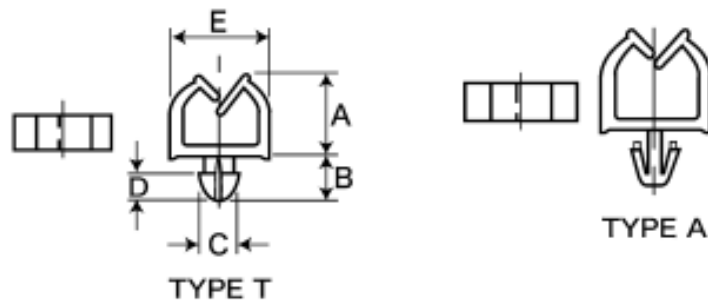

粘着式

Dimensions in mm

