

ITT 1600 W 235 V-0826

HALOTHERM | Infrared halogen lamps with white reflector



Areas of application

- Manufacture of PET bottles
- Coil coating
- Professional grills and heated counters in restaurants

Product benefits

- High efficiency
- Precise controllability
- Long lamp life
- Short response time



Technical data


Electrical data

Nominal wattage	1600.00 W
Nominal voltage	235 V
Nominal current	6.8 A
Lamp current	6.80000 A
Construction voltage	235 V

Photometrical data

Color temperature	2700 K
-------------------	--------

Dimensions & weight

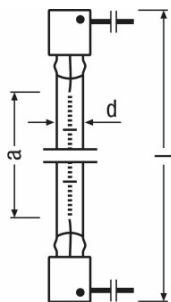

Diameter	10.0 mm
Length	222.0 mm
Filament length	157.00 mm
Cable length	200.0 mm

Lifespan

Lifespan	5000 h
----------	--------

Additional product data

Base (standard designation)	K9x15/21
Connector: Presence	Yes

Capabilities

Burning position	p15
------------------	-----

Country specific information

Product datasheet

Product code	METEL code	SEG-No.	STK-Number	UK Org
4008321206398	OSRHALOTT1600826	-	-	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4008321206398	ITT 1600 W 235 V- 0826	Folding carton box 1	303 mm x 26 mm x 26 mm	0.20 dm ³	47.00 g
4008321206404	ITT 1600 W 235 V- 0826	Shipping carton box 12	95 mm x 117 mm x 315 mm	3.50 dm ³	634.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.