

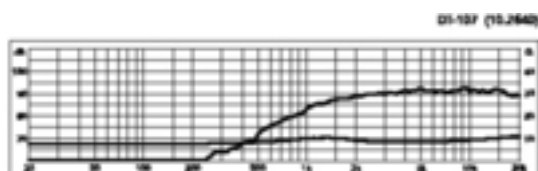


## DT-107 - HiFi Dome Tweeter

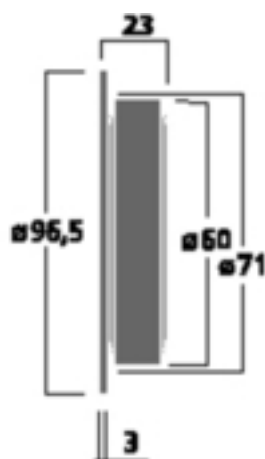

**DT-107**

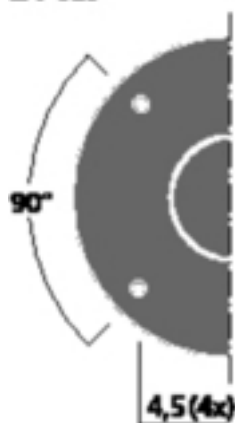

Hi-fi dome tweeter, 130 WMAX, 80 WRMS, 8 Ohm

- Textile soft dome with inside damping
- Highest linearity with good efficiency
- Extra silky and brilliant sound
- For any hi-fi application of high requirements

## Technical data

|                              |                        |
|------------------------------|------------------------|
| Impedance (Z)                | : 8 Ohm                |
| Resonant frequency (fs)      | : 1,200 Hz             |
| Max. frequency range         | : fx-22,000 Hz         |
| Rec. crossover freq. (12 dB) | : 3,000 Hz             |
| Music power                  | : 130 W <sub>MAX</sub> |
| Power rating                 | : 80 W <sub>RMS</sub>  |
| SPL (1 W/m)                  | : 89 dB                |
| Voice coil diameter          | : 25 mm                |
| Magnet diameter              | : 60 mm                |
| Mounting cutout              | : Ø 71 mm              |
| Mounting depth               | : 23 mm                |
| Dimensions                   | : Ø 96.5 mm            |
| Weight                       | : 0.3 kg               |