


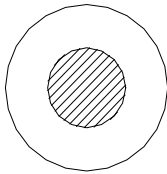

Product Name:	MIL-W-16878/4 28AWG
Product Discription:	MIL-W-16878/4 28AWG
Specification No.:	
Customer's Name:	

Description					Construction					
Rated Voltage:		600V			Conductor		Stranded Sliver plated copper			
Rated Temperature:		200℃			Size(AWG)		28			
Reference Standard:		MIL-W-16878/4			Construction(±0.008mm)		7/0.127			
Cross Section					Stranded Dia.(mm)Ref.		0.38			
					Insulation Material		PTFE			
					Insulation Color		ANY COLOR			
					Ave Thickness(mm)		0.25			
					Insulation Dia.(±0.08mm)		0.89			
Marking					Remark:					
No marking on the cable jacket					8775428 Red		8775424 Blue			
					8775412 Black		8775437 White			
					8775421 Brown					
Applications					Characteristics				Customer Approve	
These wires are ideal for internal wiring of appliances, electronic equipment and other applications.					Test Item		Standard Value		Seal & Stamp	
					Test Material		PTFE(ROHS)			
					Insulation resistance(20℃ MΩ*m		1000			
					Vol. Tesr(AC.V.60S) (V)		2000			
					Flammability Test		Horizontal flame			
Revisions					Max.DC Resistance(20℃ Ω/km)		208.66(MAX)		Signature: Date:	
Version	Description	Drawn by	Approved by	Date						
0	New document issue	Danniel	Jason	19/05/2015						