




LED Beacon with integrated siren (1 tier)

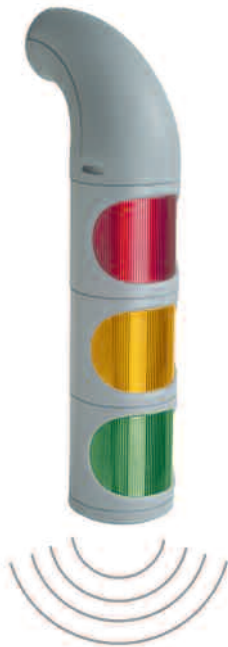

Integrated siren with high sound output up to 80 dB

- High visibility LED Beacon with integrated siren
- Colour intensive light effect thanks to LEDs in the same colour as the lenses
- Sound output up to 80 dB
- Simple mounting thanks to integrated mounting bracket
- The optical signal also offers very good sideways visibility

i TECHNICAL SPECIFICATIONS:

Dimensions (D x W x H):	1 tier: 136 mm x 85 mm x 226 mm 2 tier: 136 mm x 85 mm x 311 mm 3 tier: 136 mm x 85 mm x 396 mm
Housing:	PC/ABS, grey
Lens:	PC, transparent
Fixing:	Wall mounting
Installation position:	Vertical
Connection:	Screwable connection with wire protection max. 1.5 mm ²
Cable entry:	Cable diameter max. 13 mm
Duty cycle:	100 % ED
Tone type:	Continuous tone
Tone frequency:	50 Hz
Sound output:	> 80 dB

Life duration up to 50,000 hrs

🛒 ORDER SPECIFICATIONS:


Voltage	24 V ⁼⁼	115 bis 230 V [~]
Current Consumption LED	80 mA (red/yellow) 160 mA (green)	35 mA
Siren	35 mA	35 mA
red	494 010 55	494 010 68
green	494 020 55	494 020 68
yellow	494 030 55	494 030 68
red / green	494 060 55	494 060 68
red / yellow / green	494 080 55	494 080 68




Available from 3rd Quarter 2008



The direction of the optical signal can be individually adjusted

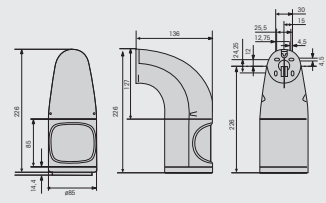

Connection diagram

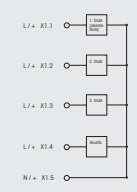

In preparation

CE	C	UL	US
1 tier, with fixing bow	2 tier, with fixing bow	3 tier, with fixing bow	IP 65
350 g	380 g	410 g	+50°C / -30°C
			> 80 dB