


Pipettes



Pipettes, Class B, Graduated, Polypropylene

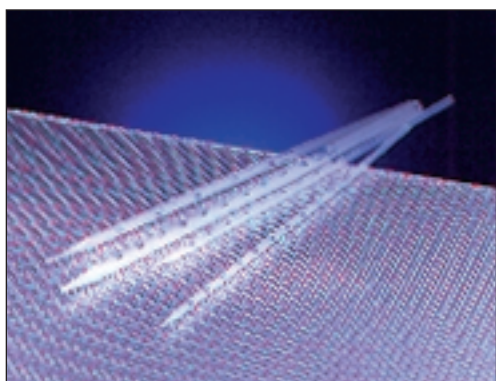


- Calibrated to class B tolerances.
- Easy to read graduation lines.
- Specially manufactured tip to ensure excellent quality.
- New & improved 10ml pipette mouthpiece for easy fitting pipettor equipment.

Reference	Capacity ml	Sub-divisions ml	Description
PDH501	1	0.1	Graduated
PDH502	2	0.1	Graduated
PDH505	5	0.1	Graduated
PDH510	10	0.1	Graduated



Exposure to temperatures above 60°C may affect accuracy. Recommend cleaning with mild alkaline detergents up to 60°C.

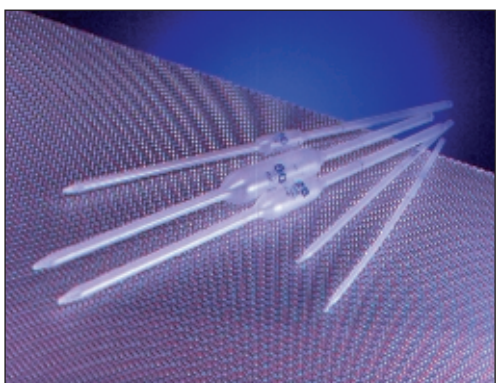

Pipettes, Class B, One Mark, Bulb Type, Polypropylene




- Calibrated to meet class B tolerances.
- Permanently marked with ring and inscriptions.

Reference	Capacity ml	Description
PDH601	1	One-mark
PDH602	2	One-mark
PDH605	5	One-mark
PDH610	10	One-mark
PDH625	25	One-mark
PDH650	50	One-mark



Exposure to temperatures above 60°C may affect accuracy. Recommend cleaning with mild alkaline detergents up to 60°C.

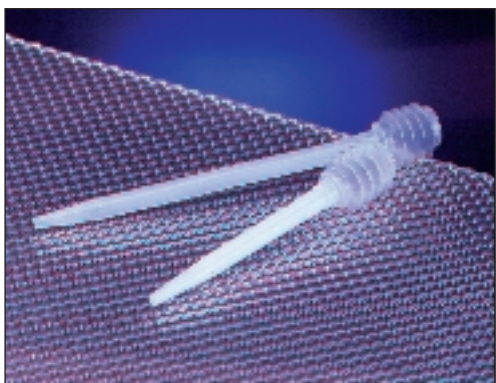

Pipettes, Dropping, Polyethylene



- Corrosion resistant and unbreakable.
- Both sizes are one-piece bellows dispensers.
- Plain stem of 7.5 mm diameter.

Reference	Capacity ml	Description
PDH404	2.5	Dropping
PDH406	4.0	Dropping