




Identification	Part No.		Pg	Drawing	Dimensions in mm
	Low construction	High construction			


Housings
bulkhead mounting

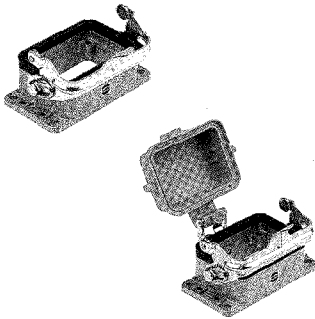

09 30 006 0301

with thermo-
plastic cover
09 30 006 0302

with metal
cover
09 30 006 0318

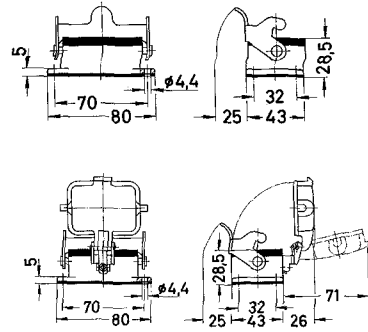

Housings

surface mounting



1 side-entry

09 30 006 1251


16

2 side-entries

09 30 006 1291

09 30 006 0292
09 30 006 0293

16
21
29

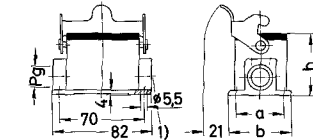

1 side-entry

09 30 006 1256

16

with metal
cover

09 30 006 2256

16


with thermo-
plastic cover

09 30 006 1296

with thermo-
plastic cover

09 30 006 0297
09 30 006 0298

16
21
29

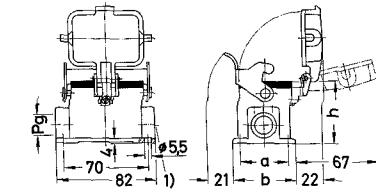

2 side-entries

with metal
cover

09 30 006 2296

with metal
cover

09 30 006 2297
09 30 006 2298


16
21
29

1) Blind way for one cable entry

	a	b	h
Low construction	40	52	54
High construction	45	57	74


Housings

Protection covers
metal

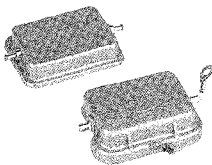

09 30 006 5404

09 30 006 5425

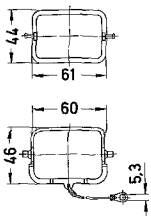

Hoods

cable to cable




09 30 006 1750

13.5


09 30 006 0752
09 30 006 0753

21
29

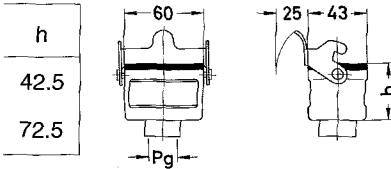

Han Hoods
Housings

 Protection cover
metal



09 30 006 5427

