


Tapered roller bearings, single row

Principal dimensions			Basic load ratings		Speed ratings	Limiting speed	Designation
d	D	T	dynamic C	static C0	Reference speed		* SKF Explorer bearir
mm			kN		r/min		-
<b>17,462</b>	39,878	13,843	21,2	20,8	13000	20000	LM 11749/710/Q

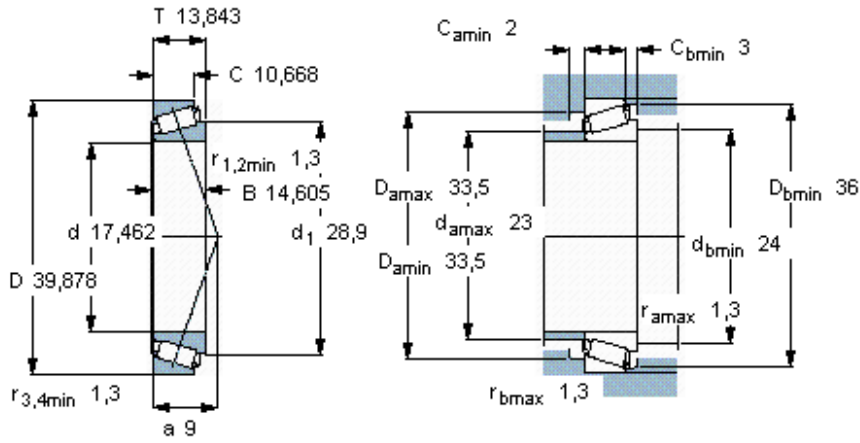

**Calculation factors**

$e = 0,28$

$Y = 2,1$

$Y_0 = 1,1$