

Products

B4MASK series | Illuminated double-pole switch quick connection 6.3 black body black bellow glossy green rocker



PRODUCT CODE: B4MASK48N1V00000

Wiring diagrams



Terminal type



sample image

accessories

Body colour



Actuator colour



Marking


Rating

16(8)A/250VAC
12(10)A/250VAC-5E4
T120/55 °C


Approvals




Dimensions (mm)

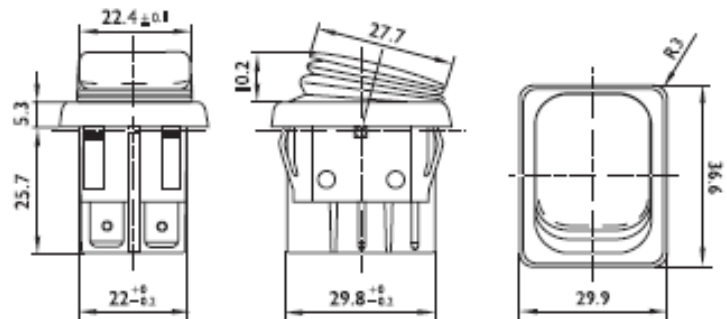

Cut out (mm)

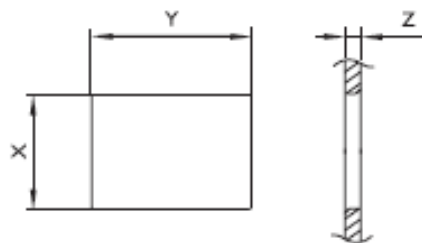

Termination

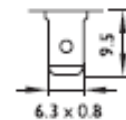

| Z | Y | X |
|----------|----------------|---------------|
| 0.7-1.25 | 30.2 ± 0.1 | 22.0 $+0.2-0$ |
| 1.25-2.0 | 30.6 ± 0.1 | 22.0 $+0.2-0$ |
| 2.0-3.0 | 30.8 ± 0.1 | 22.0 $+0.2-0$ |