
 


BULKHEAD ADAPTOR N FEMALE - SMA FEMALE
SQUARE FLANGE
R191.381.000

Série : ADAPT

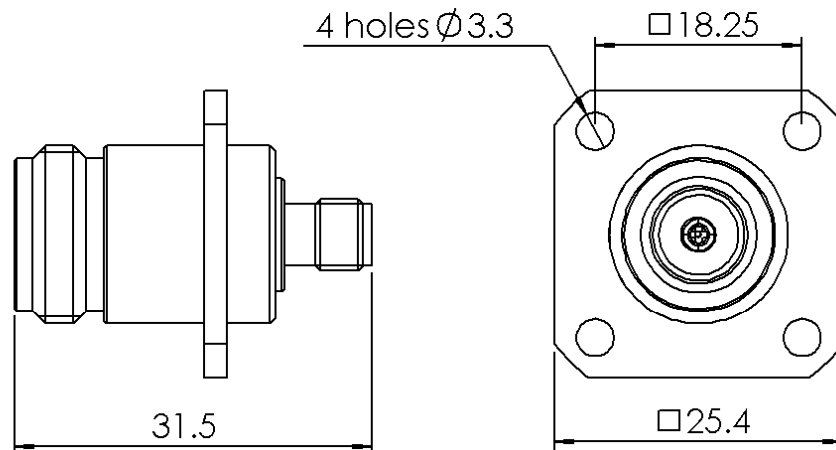

All dimensions are in mm.



COMPONENTS	MATERIALS	PLATING (μm)
BODY	LAITON	NICKEL 2
CENTER CONTACT	CUPRO BERYLLIUM	OR 0.5 SUR NICKEL 2
OUTER CONTACT	-	-
INSULATOR	PTFE	-
GASKET	-	-
OTHERS PARTS	CUPRO BERYLLIUM	NICKEL 2
-	-	-
-	-	-

Issue : 0840 D

In the effort to improve our products, we reserve the rights to make changes judged to be necessary.

RADIAL

BULKHEAD ADAPTOR N FEMALE - SMA FEMALE**R191.381.000****SQUARE FLANGE**

Série : ADAPT

PACKAGING

Standard	Unit	Other
	'W' option	Contact us

SPECIFICATION**ELECTRICAL CHARACTERISTICS**

Impedance	50	Ω
Frequency	0-11	GHz
VSWR	1.30 + 0,0000	x F(GHz) Maxi
Insertion loss	0.05	$\sqrt{F}(\text{GHz})$ dB Maxi
RF leakage	- (101)	- F(GHz)) dB Maxi
Voltage rating	500	Veff Maxi
Dielectric withstanding voltage	1000	Veff mini
Insulation resistance	5000	M Ω mini

ENVIRONMENTAL

Operating	-55/+155	$^{\circ}\text{C}$
Hermetic seal	NA	Atm.cm3/s
Panel leakage	NA	

MECHANICAL CHARACTERISTICS

Center contact retention		
Axial force – Mating end	27	N mini
Axial force – Opposite end	27	N mini
Torque	NA	N.cm mini

Recommended torque

Mating	N	0	N.cm
	SMA	0	N.cm
	-	0	N.cm
Panel nut		NA	N.cm

Mating life	500	Cycles mini
Weight	0,0000	g

OTHER CHARACTERISTICS

Issue : 0840 D

In the effort to improve our products, we reserve the rights to make changes judged to be necessary.

