


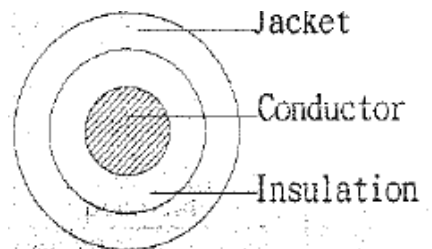

Product Name:	UL1385 28AWG
Product Discription:	UL1385 28AWG
Specification No.:	SPEC-UL1385-28AWG
Customer's Name:	

Description					Construction							
Rated Voltage:		No voltage rating			Conductor		Stranded Tinned Copper					
Rated Temperature:		125℃			Size(AWG)		28					
Reference Standard:		UL758			Construction(±0.004mm)		7/0.127					
Cross Section					Stranded Dia.(mm)Ref.		0.39					
					Insulation Material		XL-PE		Jackert Material	XL-PVDF		
					Insulation Color		White		Jacket Color		Any color	
					Ave Thickness(mm)		0.15		Ave Thickness(mm)		0.10	
					Min Thickness(mm)		0.12		Min Thickness(mm)		0.08	
					Insulation Dia.(±0.10mm)		0.70		Jacket Dia.(±0.10mm)		0.90	
Marking					Remark:							
No cable marking					8904672 Red		8904676 Blue		8904694 Grey		8904698 Violet	
					8904660 Black		8904685 White		8904682 Yellow			
					8904679 Brown		8904688 Green		8904691 Orange			
Applications					Characteristics					Customer Approve		
Internal wiring of electronic equipment.					Test Item			Standard Value			Seal & Stamp	
					Test Material			XLPE and XLPVDF(ROHS)				
					Insulation resistance(20℃ MΩ/KM			0.75				
					Vol. Tesr(AC.V.60S) (V)			500				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			239(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	YanBin	Jason	10/08/2015								