

VS-PC-2X-POF-980-SCRJ/FSMA-1

Order No.: 1657106



Assembled FO cable, break-out cable, polymer fiber 980/1000 µm, SCRJ/IP20 on FSMA/IP20, for installation inside control cabinets, length: 1 m



Commercial data	
EAN	4046356100168
Pack	1 Pcs.
Customs tariff	85447000
Weight/Piece	0.0457 KG
Catalog page information	Page 188 (PC-2007)

Product notes

WEEE/RoHS-compliant since:
05/02/2006



Technical data	
Mechanical characteristics	
Number of positions	2
Connection profile	SCRJ according to DIN EN 50377-6-1
Fiber type	Polymer Fiber
Fiber	980/1000 µm


Ferrule diameter	2.50 mm
Number of fibers	2
Insertion/withdrawal cycles	≥ 1000
External cable diameter	Twin conductor (2.2 x 4.4 mm)
Type of cable	Break-out cable
Smallest bending radius, fixed installation	30 mm
Smallest bending radius, movable installation	30 mm
Length of cable	1 m
Ambient temperature (operation)	-20 °C ... 70 °C

Material data

Housing material	PBT/nickel silver
Outer sheath, material	PE
External sheath, color	black
Ferrule material	Copper alloy
Ferrule holder color	Blue
Degree of protection	IP20

Drawings

Dimensioned drawing

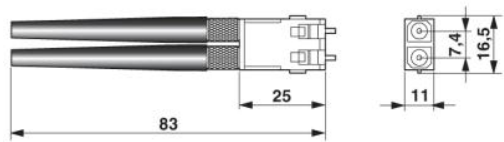

SCRJ plug connector IP20