


SR32A 325W SOLDERING IRON

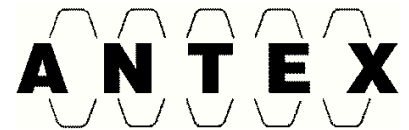

DATA SHEET


769-3160



Iron featured without bit.

SPECIFICATIONS SR32A (ANGLED) 352WATT SOLDERING IRON

NOMINAL POWER (W)	325
STANDARD VOLTAGE	230
NOMINAL TIP TEMP (°C)	430
FITTED BIT (D.F.)	7/8" (22mm)
CABLE LENGTH (m)	2.0
CABLE TYPE	Rubber with European plug
HANDLE MATERIAL	Wood
COUNTRY OF ORIGIN	U.K.
WEIGHT gms. (approx.)	1100
DIMENSIONS (approx.)	A: (bit) 50mm. B: 310mm. C: 95mm. D: 400mm.

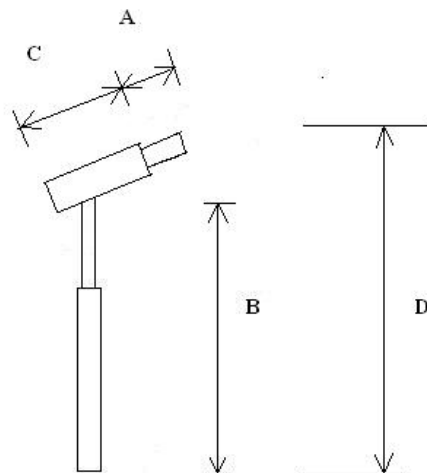

TYPICAL APPLICATIONS:

General soldering on transformer casings, soldering on commutators up to 2" dia. & tin plate & metal box fabrications.