

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [10-01-3086](#)
Status: **Active**
Overview: [SPOX™ Wire-to-Board Connectors](#)
Description: 5.08mm Pitch SPOX™ Crimp Terminal Housing, 8 Circuits

Documents:

3D Model	Product Specification PS-5197-005 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-5197-001 (PDF)	

Agency Certification

CSA	LR19980
TUV	R72090224
UL	E29179

General

Product Family	Crimp Housings
Series	5197
Application	Signal, Wire-to-Board
Overview	SPOX™ Wire-to-Board Connectors
Product Name	SPOX™
UPC	800754209601

Physical


Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Net Weight	3074.300/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.08mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	5197-08
-----------------	---------

Reference - Drawing Numbers

Product Specification	PS-5197-001, PS-5197-005, RPS-5281-001
Sales Drawing	SD-5197-N

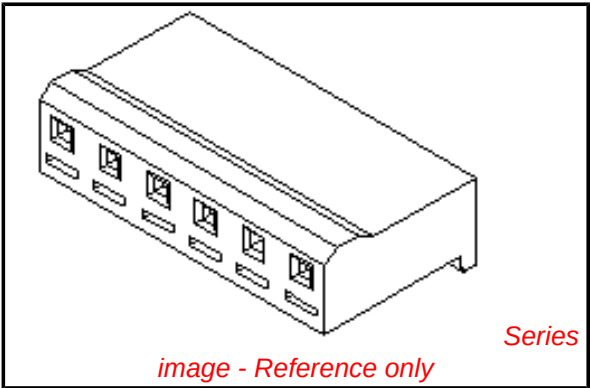

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[5197Series](#)

Mates With
[5279](#) , [5280](#) , [5281](#) , [5282](#)

Use With
[5194](#) , [5225](#)