

# Linear Double Ended High Wattage

DE 118MM ECO 120V 300W R7S SV1

0021685

## Range features



## PRODUCT OVERVIEW

|                            |                     |
|----------------------------|---------------------|
| Light colour               | 829 Warm white      |
| Ordering number            | 0021685             |
| Technology                 | Halogen             |
| Average life (Rated) (h)   | 2000                |
| Energy class               | D                   |
| Lamp shape                 | Linear              |
| Lamp finish                | Clear               |
| Dimmable                   | Yes                 |
| Cap/Base                   | R7s                 |
| Type                       | Linear Double Ended |
| EAN code                   | 5410288216850       |
| CRI (Ra)                   | 100                 |
| Colour temperature (K)     | 3000                |
| Luminous flux (Rated) (lm) | 5000                |
| Watt (Nominal) (W)         | 300                 |
| Voltage (V)                | 120                 |

# Linear Double Ended High Wattage

DE 118MM ECO 120V 300W R7S SV1

0021685

## DATA TABLE

### General data

|                                                        |                                |
|--------------------------------------------------------|--------------------------------|
| Technology                                             | Halogen                        |
| Ordering number                                        | 0021685                        |
| Average life (Nominal) (h)                             | 2000                           |
| Average life (Rated) (h)                               | 2000                           |
| Energy saving lamp                                     | No                             |
| Energy class                                           | D                              |
| Lamp finish                                            | Clear                          |
| Lamp shape                                             | Linear                         |
| Dimmable                                               | Yes                            |
| Cap/Base                                               | R7s                            |
| Type                                                   | Linear Double Ended            |
| EAN code                                               | 5410288216850                  |
| E-number FI                                            | 4749344                        |
| Product name                                           | DE 118MM ECO 120V 300W R7S SV1 |
| Lamp mercury content (mg)                              | 0                              |
| Starting time (max) (s)                                | 0.01                           |
| Warm-up time to 60% of full light (max) (s)            | Instant full light             |
| Control gear required                                  | No                             |
| Fixture rating                                         | Enclosed                       |
| IEC Reference                                          | IEC 60357                      |
| IEC Reference 2                                        | IEC 60432-3                    |
| Intended purpose                                       | General lighting               |
| No. of switching cycles before premature failure (min) | > 8000                         |
| Special purpose lamp                                   | No                             |
| Transformer required                                   | No                             |
| Sales pack quantity                                    | 10                             |
| Optimal operating condition ( ° C)                     | 25                             |

### Optical data

|                                              |                |
|----------------------------------------------|----------------|
| Light colour                                 | 829 Warm white |
| CRI (Ra)                                     | 100            |
| Suitable for accent lighting                 | No             |
| Colour temperature (K)                       | 3000           |
| Luminous flux (Rated) (lm)                   | 5000           |
| Lumen maintenance at end of nominal life (%) | 80             |
| Luminous flux (Nominal) (lm)                 | 5000           |

# Linear Double Ended High Wattage

DE 118MM ECO 120V 300W R7S SV1

0021685

## Electrical data

|                                 |     |
|---------------------------------|-----|
| kWh per 1000 hours burning time | 300 |
| Watt (Rated) (W)                | 300 |
| Watt (Nominal) (W)              | 300 |
| Voltage (V)                     | 120 |
| Lamp power factor               | 1   |

## Physical data


|                                            |                       |
|--------------------------------------------|-----------------------|
| Weight (kg)                                | 0.01                  |
| Lamp Length (mm) - C/L                     | 119.6                 |
| Max. Lamp Diameter (mm) - D                | 12                    |
| Single packaging type                      | Box/Sleeve            |
| Single package dimensions (L x W x H) (cm) | 16.50 x 2.50 x 2.90   |
| Inner package dimensions (L x W x H) (cm)  | 17.00 x 13.00 x 6.50  |
| Inner package net weight (kg)              | 0.08                  |
| Outer package dimensions (L x W x H) (cm)  | 37.50 x 28.50 x 19.50 |

## Linear Double Ended High Wattage

DE 118MM ECO 120V 300W R7S SV1

0021685

### TECHNICAL DRAWINGS

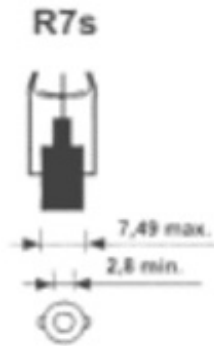

### ENERGY LABEL

