



Datasheet

Stock No: 748-2036

ENGLISH


RS Pro Black Equipment Wire, 1 mm² CSA, 1500 V 6 A 17 AWG, 100m



Cable Construction

| | |
|--------------------------|----------------------|
| Conductor | Tinned Copper |
| square(mm ²) | 1.0 |
| Construction | T0.2±0.008×32 |
| Standard Dia.(mm) | 1.30 |
| Insulation | PVC |
| Thickness | 0.6 |
| Insulation Dia.(±0.15mm) | 2.52 +0.13/-0.12 |

Design

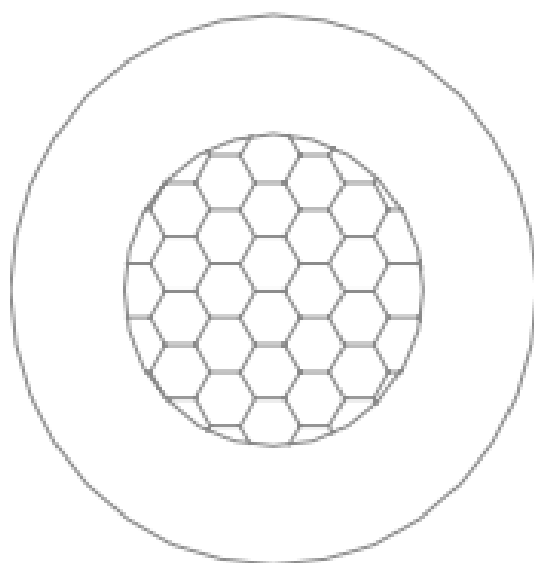

Electrical Characteristics

| | |
|--|-------|
| Max.Conductor DC Resistance at 20 °C (Ω /Km) | <18.8 |
| Min.Insulation DC Resistance at 20 °C (M Ω *Km) | 200 |
| Rated Temperature(°C) | 85 |
| Rated Voltage (V) | 1500 |