

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19041-0015](#)
Status: **Active**
Overview: Solderless Terminals
Description: Krimptite™ Ring Tongue Terminal Flag for 10-12 AWG Wire, Stud Size 10 (M5)

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Ring and Spade Terminals
Series	19041
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<u>Solderless Terminals</u>
Product Name	Krimptite™
Type	Ring
UPC	800755059304

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	1.526/g
Packaging Type	Bag
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	10 (M5)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	10, 12
Wire Size mm²	4.00 - 6.00

Material Info

Old Part Number C-144-10

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013

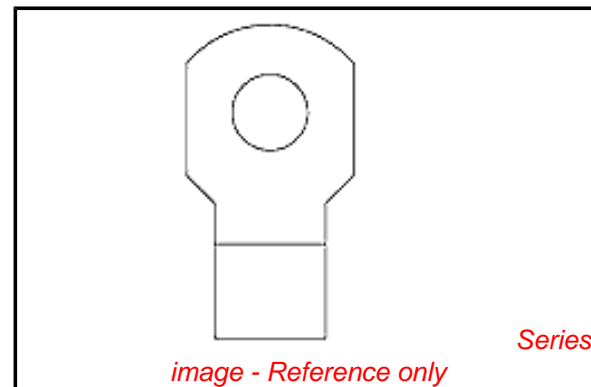


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19041Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	0640033100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640073100