


FUTURE OF LAMINATING

The Voyager A3 Laminator



100% Jam Free

Ultimate jam-free laminating when using Fellowes branded pouches

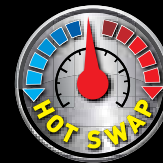

Hot Swap

Always ready to use - regardless of pouch thickness



AutoLam

Automatically detects pouch thickness and sets appropriate lamination speed



Easy Access Click and Clean

Enables maintenance of rollers for consistent lamination quality



Heatguard

Reduces the surface temperature of the laminator



Large office laminator engineered for superior results

The Voyager A3 laminator from Fellowes has been designed with unique heated belt-driven technology for jam-free laminating. It is the World's first laminator to allow automatic, instant changes between 80 and 250 micron pouches and is engineered for heavy use in busy office environments, guaranteeing excellent results every time.

www.fellowes.com

Fellowes



WHY LAMINATE?

By adding a plastic coating to paper or card, a document becomes more durable with a quality, professional-looking finish. Lamination protects documents from fingerprints, smudges and tears and also enhances the colour and contrast of the print, keeping materials in like-new condition for many years. Laminated paper or card can be used for presentation, signage, re-usable displays, and preserving frequently accessed and important documents. Using a high quality Fellowes laminator will preserve and protect your documents and important papers from everyday wear and tear.

A laminated document looks better, lasts longer.

BENEFITS OF LAMINATION:

- Laminated materials can be reused; they are wipe clean and waterproof
- Valuable graphics are protected from spills
- Strengthens documents; ideal for posters and signs
- Protects from the weather; ideal for external signage
- Improves the appearance of materials; deepens and brightens colours, enhances the contrast
- Provides a variety of finishes; gloss, matt pouches are available
- Eliminates creases and wrinkles; provides a perfect finish



WHAT TO LAMINATE?

Use a laminator at work or at home to protect, preserve, display a variety of materials.



IN THE WORKPLACE

- Maintenance checklist
- Outdoor directional signs
- Sales promotions & presentations
- Instructional materials
- Business & ID cards
- Telephone lists
- Dry-wipe calendars



IN THE HOME

- Birthday cards
- Luggage tags
- Printed digital photos
- Activity & training schedules
- Garden stakes
- Children's artwork
- School timetables

CHOOSING THE RIGHT LAMINATOR

Fellowes laminators are segmented on usage; how often they are used and the type of pouches they accept. The thicker the pouches accepted, the more versatile the machine and the more applications for which it can be used. Laminating pouches are available in different thicknesses which are measured in microns - the higher the number of microns, the thicker the pouch.

Fellowes supply 5 different types of pouch from 80 micron to 250 micron which can be used for many different applications as shown in the table below.

| Max Pouch Thickness | Level of Protection | Notices | Photos | Hobby & Craft | Certificates | Menus | External Signage |
|-------------------------------|---------------------|---------|--------|---------------|--------------|-------|------------------|
| Enhance80 MICRONS | BASIC | ✓ | ✓ | | | | |
| Impress100 MICRONS | EVERYDAY | ✓ | ✓ | ✓ | | | |
| Capture125 MICRONS | ADVANCED | ✓ | ✓ | ✓ | ✓ | | |
| Protect175 MICRONS | PREMIUM | ✓ | ✓ | ✓ | ✓ | ✓ | |
| Preserve250 MICRONS | ULTIMATE | ✓ | ✓ | ✓ | ✓ | ✓ | ✓ |



Laminators

Fellowes have made selecting a laminator easy - all you have to do is answer the following questions:

1 WHERE WILL THE LAMINATOR BE USED?

OFFICE



LARGE OFFICE
HEAVY USE
Preserve250 POUCHES



OFFICE
FREQUENT USE
Protect175 POUCHES



SMALL OFFICE
REGULAR USE
Capture125 POUCHES

PERSONAL



HOME OFFICE
MODERATE USE
Impress100 POUCHES



HOME
OCCASIONAL USE
Enhance80 POUCHES

2 WHAT SIZE DOCUMENTS DO YOU WANT TO LAMINATE?

Fellowes offer laminators with 2 different sizes of entry as shown by the icons below. The wider the throat the more flexibility there is to laminate different sized documents.



A3 = Max 32cm

Laminates all sizes up to A3 including A4, greeting cards and photographs




A4 = Max 22cm

Laminates all sizes up to A4 including A5, A6, greeting cards and photographs

3 WHICH LAMINATOR FEATURES WILL MAKE YOUR JOB EASIER?

With their many innovative and user-friendly features, Fellowes laminators are more efficient, easier and safer to use than ever. Look for these icons and their descriptions in the Laminator product pages.

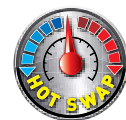


*when using Fellowes branded pouches



Office Laminators

| Image | Features | Code | Pack Qty | Product Dimensions (HxWxD - mm) & Weight | Retail Barcode | Outer Dimensions (HxWxD - mm) & Weight | Outer Barcode |
|-------|----------|------|----------|--|----------------|--|---------------|
|-------|----------|------|----------|--|----------------|--|---------------|




Jupiter A3 Laminator Office Laminator -

| | | | | | | | |
|---|--|--|---|---------------------------|---|---------------------------|---|
|  | <ul style="list-style-type: none"> • Easy to use laminator for frequent use • LED user interface makes using the laminator easy • Manual reverse function | 5701801 | 1 | 116 x 554 x 220 6.76kg | 043859511129 | 338 x 218 x 640 8.78kg | 50043859511124 |
| | |  | | |  | |  |

See page 19 for Laminator Roller Wipes

| | Entry Width | Rollers | Heat-Up Time | Temp | Speed | Display | Misfeed Mech | Microns | Starter Kit | Warranty |
|-------------------|-------------|---------|--------------|------|----------|-----------|----------------|---------|-------------|----------|
| Jupiter A3 | 330mm | 4 | 4mins | 5 | 50cm/min | Logic LED | Manual Reverse | 80-175 | 10 doc | 2 yr |




Neptune A3 Laminator Office Laminator *Price: R3,499 Incl. VAT

| | | | | | | | |
|---|---|--|---|--------------------------|---|---------------------------|----------------|
|  | <ul style="list-style-type: none"> • Reliable laminator for quality lamination of up to 175 micron pouches • LED user interface makes using the laminator easy • Manual reverse function | 5705001 | 1 | 130 x 560 x 223 5.5kg | 0043859569601 | 194 x 614 x 286 6.62kg | 50043859569606 |
| | |  | | |  | | |

| | Entry Width | Rollers | Heat-Up Time | Temp | Speed | Display | Misfeed Mech | Microns | Starter Kit | Warranty |
|-------------------|-------------|---------|--------------|------|----------|-----------|----------------|---------|-------------|----------|
| Neptune A3 | 330mm | 4 | 4mins | 4 | 50cm/min | Logic LED | Manual Reverse | 80-175 | No | 2 yr |

Small Office Laminator

Saturn A4 & Saturn A3 Small Office Laminators - Regular Use

| | | | | | | | |
|---|---|----------------------|---|--------------------------|---------------|---------------------------|----------------|
|  | <ul style="list-style-type: none"> • Quality lamination of up to 125 micron pouches • Front flap serves as document guide and dust cover • Release mechanism for clearing mis-fed documents • Carry handle & stand-up feet with cable tidy for vertical storage | Saturn A3 5701601 | 2 | 90 x 502 x 200 3.14kg | 0043859511105 | 250 x 320 x 554 8.48kg | 50043859511100 |
| | | Saturn A4 5701401 | 2 | 86 x 410 x 202 2.36kg | 0043859511082 | 266 x 318 x 464 6.72kg | 50043859511087 |
|  | | |  | | | | |

| | Entry Width | Rollers | Heat-Up Time | Temp | Speed | Display | Misfeed Mech | Microns | Starter Kit | Warranty |
|------------------|-------------|---------|--------------|------|----------|-----------|----------------|---------|-------------|----------|
| Saturn A4 | 220mm | 2 | 6mins | 2 | 30cm/min | Basic LED | Manual Release | 80-125 | 10 doc | 2 yr |
| Saturn A3 | 330mm | 2 | 6mins | 2 | 30cm/min | Basic LED | Manual Release | 80-125 | 10 doc | 2 yr |



Glossy Laminating Pouches

| | Thickness | Size | Qty/Pack | Code | Pack Dimensions (HxWxD - mm) & Weight | Retail Barcode | Outer | Outer Dimensions (HxWxD - mm) & Weight | Outer Barcode |
|--|-----------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|
|--|-----------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|

Enhance80^{MICRONS} Glossy Pouches



| | | | | | | | | |
|--------|----|-----|---------|-------------------------|--------------|----|--------------------------|----------------|
| 80 mic | A3 | 100 | 53062 | 432 x 306 x 22 / 2.26kg | 077511530623 | 5 | 116 x 334 x 456 / 12kg | 50077511554792 |
| 80 mic | A3 | 25 | 53964 | 470 x 320 x 5 / 0.6kg | 077511539640 | 5 | 36 x 460 x 335 / 3.28kg | 50077511556567 |
| 80 mic | A4 | 100 | 5306101 | 306 x 220 x 18 / 1.16kg | 077511530616 | 5 | 112 x 244 x 326 / 6.08kg | 50043859471961 |
| 80 mic | A4 | 25 | 53962 | 348 x 232 x 6 / 0.32kg | 077511539626 | 10 | 68 x 252 x 340 / 3.38kg | 50077511556543 |
| 80 mic | A5 | 100 | 53060 | 220 x 160 x 20 / 0.6kg | 077511530609 | 5 | 110 x 186 x 248 / 3.2kg | 50077511554815 |
| 80 mic | A5 | 25 | 53960 | 262 x 176 x 4 / 0.1kg | 077511539602 | 20 | 108 x 190 x 250 / 3.2kg | 50077511556581 |

Impress100^{MICRONS} Glossy Pouches



| | | | | | | | | |
|---------|----|-----|-------|-------------------------|---------------|----|--------------------------|----------------|
| 100 mic | A3 | 100 | 53512 | 430 x 308 x 24 / 2.98kg | 077511535123 | 5 | 136 x 330 x 450 / 15.4kg | 50077511554884 |
| 100 mic | A4 | 100 | 53511 | 308 x 220 x 24 / 1.56kg | 077511535116 | 10 | 244 x 242 x 328 / 16.3kg | 50077511554853 |
| 100 mic | A5 | 100 | 53510 | 222 x 158 x 24 / 0.8kg | 0077511535109 | 5 | 130 x 180 x 236 / 4.14kg | 50077511554860 |

Capture125^{MICRONS} Glossy Pouches



| | | | | | | | | |
|---------|----------|-----|---------|-------------------------|---------------|----|---------------------------|----------------|
| 125 mic | A2 | 50 | 53093 | 598 x 432 x 20 / 4.1kg | 077511530937 | 3 | 70 x 454 x 632 / 12.84kg | 50077511554877 |
| 125 mic | A3 | 100 | 53075 | 430 x 306 x 30 / 3.84kg | 077511530753 | 5 | 158 x 330 x 452 / 19.94kg | 50077511554884 |
| 125 mic | A3 | 25 | 53965 | 478 x 316 x 6 / 0.98kg | 077511539657 | 5 | 52 x 336 x 462 / 5.22kg | 50077511556574 |
| 125 mic | A4 | 100 | 53074 | 308 x 220 x 30 / 1.94kg | 077511530746 | 10 | 296 x 242 x 328 / 20kg | 50077511554891 |
| 125 mic | A4 | 25 | 53963 | 352 x 234 x 10 / 0.52kg | 077511539633 | 10 | 88 x 244 x 330 / 5.44kg | 50077511556550 |
| 125 mic | A5 | 100 | 53073 | 226 x 160 x 28 / 1.02kg | 077511530739 | 5 | 160 x 178 x 244 / 5.34kg | 50077511554907 |
| 125 mic | A5 | 25 | 53961 | 258 x 168 x 8 / 0.22kg | 077511539619 | 20 | 160 x 192 x 248 / 5.3kg | 50077511556598 |
| 125 mic | A6 | 100 | 53072 | 160 x 116 x 28 / 0.52kg | 077511530722 | 10 | 162 x 182 x 250 / 5.38kg | 50077511554914 |
| 125 mic | 83x113mm | 100 | 53071 | 120 x 88 x 28 / 0.3kg | 077511530715 | 10 | 162 x 140 x 194 / 3.12kg | 50077511555010 |
| 125 mic | 75x105mm | 100 | 53069 | 110 x 80 x 30 / 0.24kg | 077511530692 | 10 | 172 x 130 x 182 / 2.6kg | 50077511530697 |
| 125 mic | 65x95mm | 100 | 53067 | 100 x 68 x 30 / 0.2kg | 077511530678 | 10 | 164 x 126 x 164 / 2.04kg | 50077511554938 |
| 125 mic | 65x95mm | 50 | 53968 | 118 x 70 x 18 / 0.12kg | 0077511539688 | 10 | 104 x 128 x 164 / 1.1kg | 50077511556635 |
| 125 mic | 60x90mm | 100 | 5397401 | 98 x 66 x 30 / 0.16kg | 043859526338 | 10 | 164 x 112 x 148 / 1.8kg | 50043859526333 |
| 125 mic | 54x86mm | 100 | 53063 | 88 x 58 x 28 / 0.14kg | 077511530630 | 10 | 162 x 110 x 144 / 1.54kg | 50077511554945 |
| 125 mic | 54x86mm | 50 | 53966 | 112 x 56 x 18 / 0.08kg | 0077511539664 | 10 | 104 x 122 x 146 / 0.86kg | 50077511556604 |

Protect175^{MICRONS} Glossy Pouches



| | | | | | | | | |
|---------|----|-----|---------|-------------------------|---------------|----|---------------------------|----------------|
| 175 mic | A3 | 100 | 53088 | 40 x 306 x 432 / 5.46kg | 077511530883 | 4 | 136 x 332 x 446 / 16.94kg | 50077511555034 |
| 175 mic | A4 | 100 | 53087 | 308 x 222 x 40 / 2.7kg | 077511530876 | 5 | 216 x 238 x 328 / 14.08kg | 50077511555041 |
| 175 mic | A4 | 25 | 5325701 | 350 x 244 x 10 / 0.66kg | 0043859535422 | 10 | 116 x 260 x 338 / 7.16kg | 50043859535427 |

Preserve250^{MICRONS} Glossy Pouches



| | | | | | | | | |
|---------|----|-----|-------|-------------------------|--------------|---|---------------------------|----------------|
| 250 mic | A4 | 100 | 54018 | 306 x 222 x 54 / 3.76kg | 077511540189 | 4 | 232 x 242 x 330 / 15.48kg | 50077511555188 |
|---------|----|-----|-------|-------------------------|--------------|---|---------------------------|----------------|



Laminating Supplies

Glossy Laminating Pouches

| | Thickness | Size | Qty/Pack | Code | Pack Dimensions (HxWxD - mm) & Weight | Retail Barcode | Outer | Outer Dimensions (HxWxD - mm) & Weight | Outer Barcode |
|--|-----------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|
|--|-----------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|

Enhance⁸⁰ MICRONS

Adhesive Back Pouches



| | | | | | | | | |
|--------|----|-----|-------|-------------------------|--------------|---|--------------------------|----------------|
| 80 mic | A3 | 100 | 53023 | 432 x 310 x 28 / 3.46kg | 077511530234 | 3 | 96 x 330 x 454 / 10.46kg | 50077511555263 |
| 80 mic | A4 | 100 | 53022 | 310 x 222 x 24 / 1.72kg | 077511530227 | 5 | 154 x 242 x 330 / 8.92kg | 50077511555256 |

Glossy Photo Pouches

| | | | | | | | | |
|--------|---------|----|---------|------------------------|--------------|----|-------------------------|----------------|
| 80 mic | 10x15cm | 25 | 54406 | 210 x 126 x 4 / 0.08kg | 077511544064 | 10 | 74 x 144 x 194 / 0.9kg | 50077511544069 |
| 80 mic | 13x18cm | 25 | 5359501 | 224 x 146 x 4 / 0.12kg | 043859539192 | 10 | 72 x 158 x 208 / 1.24kg | 50043859539197 |

Pre-Punched A4 Pouches

| | | | | | | | | |
|--------|-----------|-----|---------|-------------------------|---------------|----|--------------------------|----------------|
| 80 mic | 228x303mm | 100 | 5452501 | 310 x 232 x 18 / 1.22kg | 0043859521821 | 10 | 198 x 254 x 334 / 12.7kg | 50043859521826 |
|--------|-----------|-----|---------|-------------------------|---------------|----|--------------------------|----------------|

Matt Pouches

| | | | | | | | | |
|--------|----|-----|---------|------------------------|---------------|----|---------------------------|----------------|
| 80 mic | A3 | 100 | 5452001 | 426 x 304 x 20 / 2.3kg | 043859522323 | 5 | 110 x 330 x 448 / 11.88kg | 50043859522328 |
| 80 mic | A4 | 100 | 5452101 | 304 x 218 x 22 / 1.2kg | 0043859522330 | 10 | 200 x 240 x 332 / 12.28kg | 50043859522335 |

Value packs 250pcs



| | | | | | | | | |
|---------|----|-----|---------|-------------------------|---------------|---|---------------------------|----------------|
| 80 mic | A4 | 250 | 5312901 | 318 x 238 x 52 / 2.96kg | 0043859521838 | 4 | 218 x 262 x 340 / 12.28kg | 50043859521833 |
| 100 mic | A4 | 250 | 5313901 | 320 x 242 x 64 / 3.9kg | 043859521845 | 4 | 264 x 262 x 340 / 16.1kg | 50043859521840 |
| 125 mic | A4 | 250 | 5314901 | 320 x 242 x 76 / 5.1kg | 0043859521852 | 4 | 316 x 260 x 342 / 20.82kg | 50043859521857 |

Lamination Accessories

| Description | Size | Qty/Pack | Code | Pack Dimensions (HxWxD - mm) & Weight | Retail Barcode | Outer | Outer Dimensions (HxWxD - mm) & Weight | Outer Barcode |
|-------------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|
|-------------|------|----------|------|---------------------------------------|----------------|-------|--|---------------|

Carrier & Cleaning Sheets

| | | | | | | | | |
|--|----|----|---------|------------------------|--------------|----|-------------------------|----------------|
| | A4 | 10 | 5320601 | 356 x 232 x 6 / 0.16kg | 043859522163 | 20 | 78 x 246 x 334 / 3.42kg | 50043859522168 |
|--|----|----|---------|------------------------|--------------|----|-------------------------|----------------|

Laminator Roller Wipes



| | | | | | | | |
|-----------|----|---------|------------------------|--------------|---|--------------------------|----------------|
| Tub of 50 | 50 | 5703701 | 172 x 80 x 80 / 0.18kg | 043859528127 | 6 | 184 x 178 x 252 / 1.32kg | 50043859528122 |
|-----------|----|---------|------------------------|--------------|---|--------------------------|----------------|



Identification and Badges

| | | | | | | | | |
|-----------------------------------|----------|-----|---------|--------------------------|---------------|----|---------------------------|----------------|
| European Clip with straps | 56x92mm | 100 | 53030 | 28 x 154 x 150 / 0.58kg | 0077511530302 | 5 | 160 x 162 x 160 / 2.96kg | 50077511556000 |
| Pin Clip Badge Clear PVC | 56x92mm | 50 | 53041 | 216 x 142 x 71 / 0.46kg | 0077511530418 | 10 | 351 x 231 x 297 / 4.96kg | 50077511555904 |
| Security Badge with Metal Clip | 90x60mm | 50 | 53043 | 168 x 116 x 68 / 0.7kg | 0077511530432 | 5 | 344 x 124 x 178 / 3.42kg | 50077511555881 |
| Protect Card Holder + Clip | 90x60mm | 50 | 53044 | 78 x 182 x 194 / 1.18kg | 077511530449 | 5 | 402 x 188 x 202 / 6.04kg | 50077511555942 |
| Name Support | 45x120mm | 50 | 53045 | 218 x 138 x 68 / 0.6kg | 0077511530456 | 40 | 350 x 454 x 566 / 25.36kg | 50077511530451 |
| Name Support | 60x250mm | 25 | 53046 | 262 x 148 x 60 / 0.76kg | 0077511530463 | 30 | 304 x 458 x 548 / 23.78kg | 50077511530468 |
| Lanyard neck strap with Breakaway | | 50 | 5325501 | 80 x 180 x 145 / 0.624kg | 043859525331 | 20 | 420 x 380 x 305 / 13.72kg | 50043859525336 |