


Verbatim LED MR11 GU4 2W 2700K Warm White 90 LM



- GU4 Socket
- 12V AC/DC Voltage
- 25,000 hours Lifetime
- 82% Energy Saving
- Lumen: 90
- Equivalent to 15W incandescent bulb

Product Number	52144
General Data	
Lamp Socket	GU4
Electric Data	
Wattage (W)	2
Wattage Equivalent (W)	15
Voltage (V)	12V AC/DC
Dimmable	no
Power Factor	0.65
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	41
Diameter (in mm)	35
Weight (g)	18
Photometric Data	
Luminous Flux (lm)	90
CRI	80
CCT (K)	2700
Luminous Intensity (cd)	200
Beam Angle (°)	35
Luminous Efficacy (lm/W)	45
Lifetime (hrs)	25,000
Switching Cycle	40,000

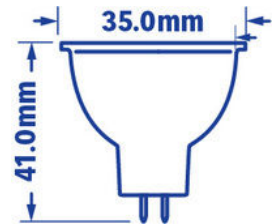


02/07/2014

Photometric Diagrams

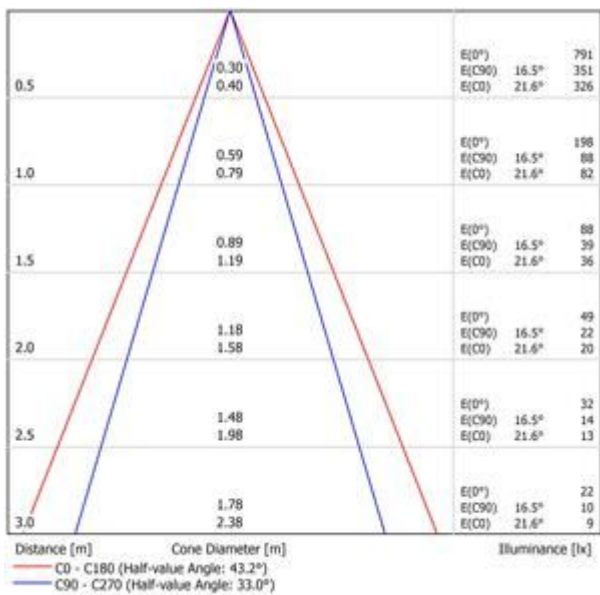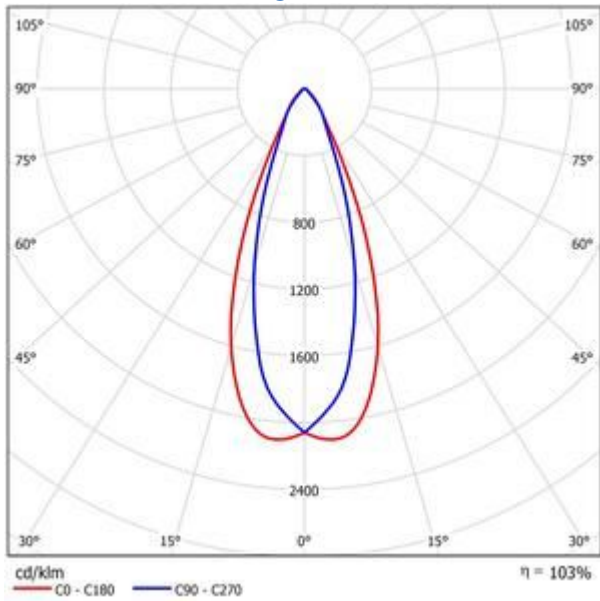

Energy Rating

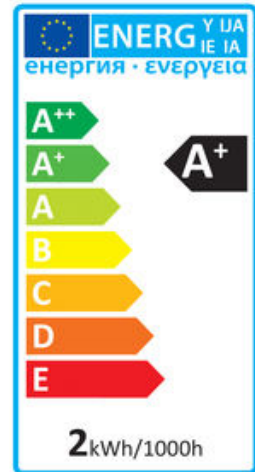

Technical Packaging Details

Barcode

023942521440

EAN 128

(02)00023942521440(37)06(91)14

EAN 14

50023942521445

Pack Dimensions(HxWxL)

136 x 36 x 90

Pack Weight

29

MOQ

6

Carton Dimensions (HxWxL)

145 x 110 x 188

Cartons/Pallet

198

Layers/Pallet

6

Units/Pallet

1188

02/07/2014