

## Product

### TK PC 2518-9-tm



Empty enclosure - Industrial Quality -, box: glass fibre reinforced polycarbonate, grey, similar to RAL 7035, cover: polycarbonate, transparent

with metric knockouts

**Article:** TK PC 2518-9-tm

### Technical Data

#### Dimensions:

Width:	254 mm
Length:	180 mm
Height:	90 mm
interior height:	76 mm

#### material:

Base:	Polycarbonate, glass-fibre reinforced, grey simila
Cover:	Polycarbonate, transparent
Sealing:	Polyurethane
Cover screw:	Polyamide 6, fiber-glass reinforced


#### Properties:

Ingress protection:	IP66 - acc. EN 60529 / DIN VDE 0470-1
Ambient temperature (min.):	-35 °C
Ambient temperature (max.):	80 °C
Ambient temperature (24 h):	60 °C
Max. rel. humidity at 40° C:	50%

Max. rel. humidity at 25° C (short Therm):	{100%}
Rated insulation voltage AC:	690V
Impact resistance:	{IK08 nach DIN EN 5012 / VDE 0470 Teil 100 }
Protection class:	II - isolate protection acc. VDE 0106 Protective insulation as per VDE 0106
Halogen-free:	√
Heavy metals-free:	√
PVC-free:	√
Silicone-free:	√
UV resistance:	√
Weatherproof:	√
Combustion behaviour to UL:	5VA nach UL 50 / UL 746C
Combustion behaviour to UL:	{V-2 nach UL 94}
Combustion behaviour to VDE:	960°C acc. VDE 0471/ EN 60695
Fitted for outdoor application:	√
Knockouts:	√

---

## Drawing

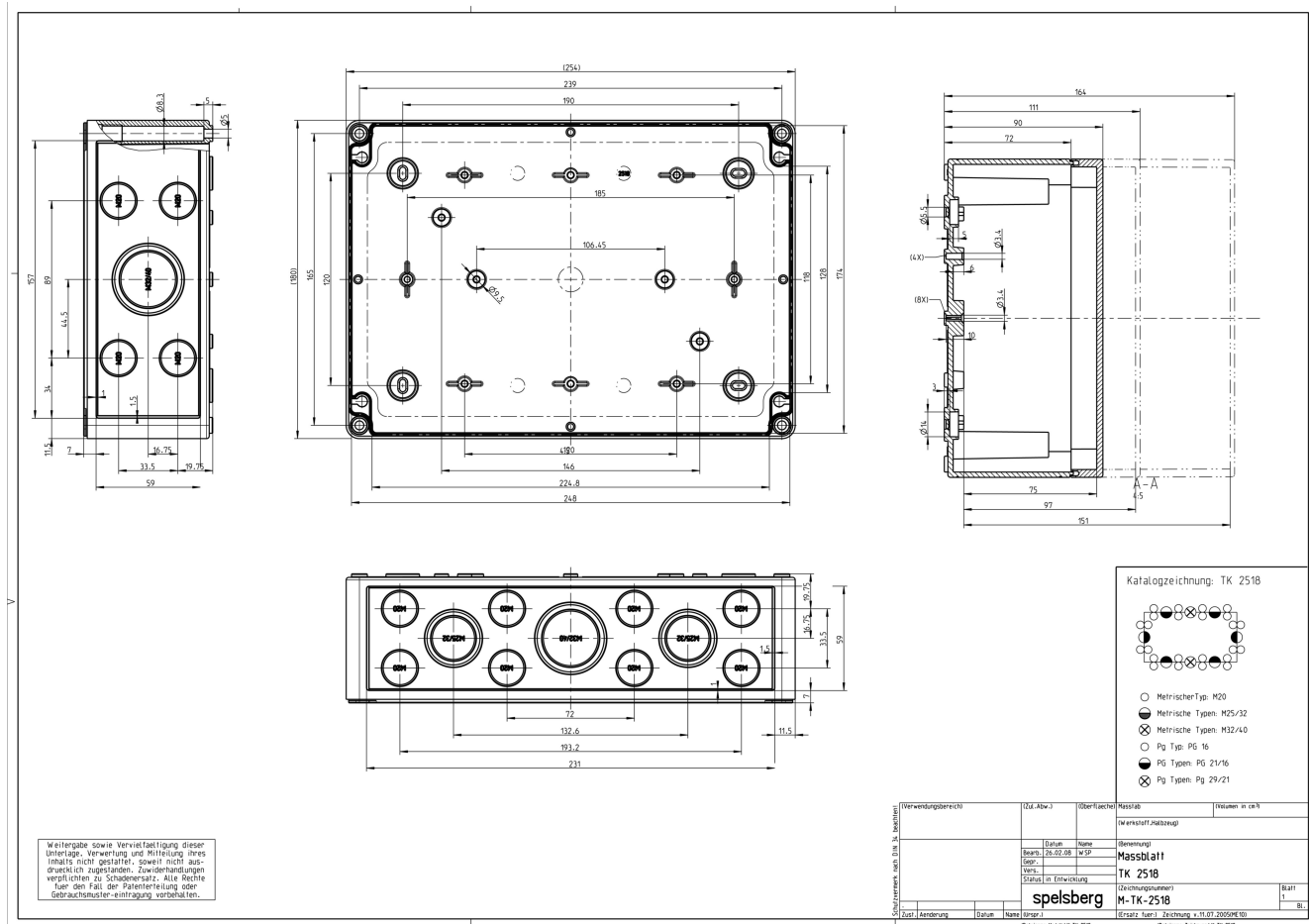

## Manufacturer

Günther Spelsberg GmbH + Co. KG  
 Im Gewerbepark 1  
 58579 Schalksmühle  
 +49 (0)2355/892-0  
 +49 (0)2355/892-299  
 www.spelsberg.de