


Cable Accessories

3M™ Cable Clips

Adhesive Cable Clips 700 Series

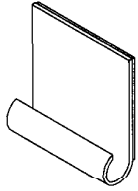


3M adhesive cable clips 700 series are made of formed vinyl material backed with a pressure-sensitive foam adhesive. They may be mounted to most clean, dry surfaces without drilling. Clips will accommodate cables with diameters from 0.125 to 0.375" (3 to 10 mm), and if desired, a

tight fit may be selected to keep cable from slipping. Applications include internal equipment wiring, supporting and protecting wire and cable systems around equipment cabinets, and other inside-plant uses. 3M cable clips are gray.

Product	UPC	O.D. Range/Length	Inner Unit Pack	Case Qty.
706	12972	0.125" Nominal, Length - 1.0"	100/bag	1000
707	30445	0.250" Nominal, Length - 1.00"	100/bag	1000
708	12998	0.187" Nominal, Length - 1.25"	100/bag	1000
710	13012	0.250" Nominal, Length - 1.5"	100/bag	1000
712	21387	0.312" Nominal, Length - 1.75"	100/bag	1000
713	21429	0.375" Nominal, Length - 2.0"	100/bag	1000

UPC prefix 054007-.

Adhesive Cable Clips 800 Series

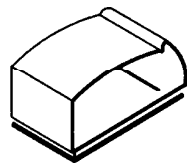

3M adhesive cable clip 800 series are made of the same tough vinyl material as the 700 Series and is used to secure wire and cable. The adhesive foam backing adheres to a variety of clean, dry surfaces with excellent holding

power. Clips snap open to accept cables and may then be closed to hold them in place and hide them from view. Clips are gray.

Product	UPC	O.D. Range/Length	Inner Unit Pack	Case Qty.
805G	30170	Up to 0.375" Nominal, Duct Length - 1.0"	100/bin	1000
805G	30169	Up to 0.375" Nominal, Duct Length - 1.0"	1000/bin	1000

UPC prefix 054007-.

3M™ Cable Ties & Bases

3M cable ties secure wire bundles, harnesses and components quickly, without slipping. The self-locking head with heavy double teeth on the one-piece pawl assures the reliability you've come to expect from 3M.

Molded from 6/6 nylon, 3M cable ties are designed to meet temperatures from -40°C/-40°F to 85°C/185°F. They are available in a variety of sizes and styles as well as weather-resistant black nylon for outdoor use. Our cable ties are UL Recognized. UL File No. E116841.

Cable Tie Assortment Pack

The assortment pack contains 100 of our most commonly used ties — three sizes, four lengths and both colors.

Product	UPC	Pack Contents	Case Qty.
06220	06220	15 Natural color, miniature ties 4" (102 mm) 10 Weather resistant black, miniature ties 4" (102 mm) 15 Natural color, intermediate ties 5" (127 mm) 10 Weather resistant black, intermediate ties 5" (127 mm) 15 Natural color, standard ties 7.5" (190.5 mm) 10 Weather resistant black, standard ties 7.5" (190.5 mm) 15 Natural color, standard ties 11" (279.4 mm) 10 Weather resistant black, standard ties 11" (279.4 mm)	100

Note: The Assortment Pack is not UL Recognized.

UPC prefix 054007-.

Miniature Cable Ties



Natural

Product	UPC	Approx. Length	Approx. Max. Bundle Diameter	Approx. Width	Approx. Thickness	Loop Tensile	Inner Unit Pack
06224	06224	4" (102 mm)	0.7" (17.8 mm)	0.1" (2.54 mm)	0.04" (1.02 mm)	18 lbs. (79.9 N)	100 bag
06248	06248	4" (102 mm)	0.7" (17.8 mm)	0.1" (2.54 mm)	0.04" (1.02 mm)	18 lbs. (79.9 N)	1000 bag

Weather Resistant Black

Product	UPC	Approx. Length	Approx. Max. Bundle Diameter	Approx. Width	Approx. Thickness	Loop Tensile	Inner Unit Pack
06200	06200	4" (102 mm)	0.7" (17.8 mm)	0.1" (2.54 mm)	0.04" (1.02 mm)	18 lbs. (79.9 N)	100 bag
06270	06270	4" (102 mm)	0.7" (17.8 mm)	0.1" (2.54 mm)	0.04" (1.02 mm)	18 lbs. (79.9 N)	1000 bag

UPC prefix 054007-.

Intermediate Cable Ties



Natural

Product	UPC	Approx. Length	Approx. Max. Bundle Diameter	Approx. Width	Approx. Thickness	Loop Tensile	Inner Unit Pack
06225	06225	5.88" (149 mm)	1.25" (31.8 mm)	0.14" (3.66 mm)	0.05" (1.14 mm)	30 lbs. (133 N)	100 bag
06249	06249	5.88" (149 mm)	1.25" (31.8 mm)	0.14" (3.66 mm)	0.05" (1.14 mm)	30 lbs. (133 N)	1000 bag

Weather Resistant Black

Product	UPC	Approx. Length	Approx. Max. Bundle Diameter	Approx. Width	Approx. Thickness	Loop Tensile	Inner Unit Pack
06201	06201	5.88" (149 mm)	1.25" (31.8 mm)	0.14" (3.66 mm)	0.05" (1.14 mm)	30 lbs. (133 N)	100 bag
06271	06271	5.88" (149 mm)	1.25" (31.8 mm)	0.14" (3.66 mm)	0.05" (1.14 mm)	30 lbs. (133 N)	1000 bag

UPC prefix 054007-.

3M Electronic Products Division

<http://www.3M.com/interconnects/>