




Peli lights - Diving Light - Submersible Incandescent Diving Lights

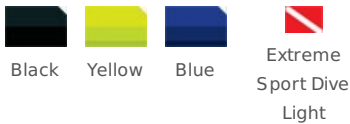

The Nemo 4300 is the ultimate dive light. The 4300 has an unbreakable ABS body with thermoplastic over-moulded accents and polycarbonate lens. It uses a clever magnetic switch that operates outside of the body to prevent leaking. The switch can be easily removed for washing off sand and dirt. Peli's unique battery compartment design allows for optimal space utilization and negative buoyancy. A spare Xenon lamp is included and stored underneath the reflector. Submersible to 100 meters and powered by 8 C alkaline cells.



Peli lights - Diving Light - Submersible Incandescent Diving Lights
ANSI FL1 Specifications

LIGHT SOURCE.	High Xenon
BATTERIES	8 C Alkaline (Not included)
CHARGE TIME	N/A
VOLTAGE	12
LENGTH	19 cm (7.5")
WEIGHT W/ BATTERIES	0.34 kg (12 oz.)
WEIGHT W/O BATTERIES	0.47 kg (16.64 oz.)

LIGHT OUTPUT	High
RUNTIME (hours/min)	6h
BEAM DISTANCE (meters)	143m
PEAK BEAM INTENSITY (candela)	5222cd
WATERPROOF & SUBMERSIBLE	100m

Materials

Body	Lens	Shroud	Switch Type
ABS Resin	Polycarbonate Resin	Thermoplastic Rubber	On/Off magnetic switch
Clip	Contact, Spring & Retainer	O-Ring	Night Vision Film
N/A	Stainless Steel and Phosphore Bronze	Ethylene Propylene	N/A

Configuration

Cat. #	Description
--------	-------------

Peli lights - Diving Light - Submersible Incandescent Diving Lights Accessories

Cat. #	Description
4303	Nemo™ 4300 2 Pack Replacement Lamps