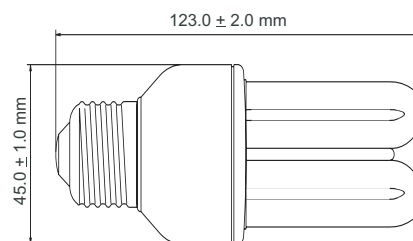
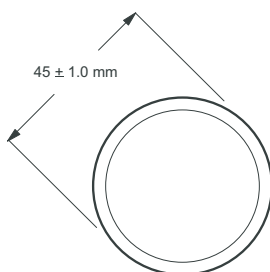


SYLVANIA**COMPACT
FLUORESCENT LAMP****MINI-LYNX
HOME T3 TU
STICK 11W****DIMENSIONS (mm)**

Cap Type: E27 - EN60061-1 sheet -7004-21

ELECTRICAL DATA¹

		<u>Nominal Value</u>	<u>Min.</u>	<u>Max.</u>
Lamp rated wattage	(W) :	11W		12.1W
Lamp operating voltage (rms)	(V) :	230-240V		
Lamp current	(mA) :	90 mA		
Power Factor	:		0.55	

OPERATING CONDITIONS:

Cap Rim temperature	(°C) :			80
Lamp Ambient Temperature	(°C) :	25	-10	60
Operating Position	:	Unrestricted		
Weight	(g) :	65g		

PERFORMANCE SPECIFICATIONS :

Starting time at 25°C	(s) :			0.3
Warm up Time to 60% stabilized light output	(s) :			30
² Switching Cycles (to 50% Failure)	:		4000	

LAMP LIFE³

Average life (IEC Test Cycle)	(h) :	8000
-------------------------------	-------	------

PHOTOMETRIC DATA:

	colour no.	Luminous Flux nominal value (lm)	CRI (Class)	Colour Temp. (K)	Energy Efficiency Class	ILCOS Code
Homelight Deluxe	827	645	1b	2700	A	FBT-11/27/1b-E27-45/123
Cool White Deluxe	840	645	1b	4000	A	FBT-11/40/1b-E27-45/123
Daylight Deluxe	865	600	1b	6500	A	FBT-11/65/1b-E27-45/123

Attention: Lamps comply with EN 60 968 (Safety Requirements) and EN 60 969 (Performance Requirements) and CE Regulations.¹Measured according to EN 60 969, at 50 Hz, lamp aged 100h.²Switching Cycle ON time 60s; OFF time 180s, at rated Voltage.³Life test according to EN 60 969.Hg
3.0mg

Issued by : R & D Noida
Date : 01.05.2011
Revision Date :

DATA SHEET

Specification No. : T1003
Supersedes :
Page : 1 of 1

HAVELLS SYLVANIA reserves the right to change data and specification without notice.
Data for guidance only.

SYLVANIA