


# Verbatim LED PAR16 GU10 7.3W 2700K Warm White 390 LM DIM


- GU10 Socket
- 220 - 240 V Voltage
- 35,000 hours Lifetime
- Dimmable
- 87% Energy Saving
- Equivalent to 56W incandescent bulb

Product Number	52234
<b>General Data</b>	
Lamp Socket	GU10
<b>Electric Data</b>	
Wattage (W)	7.3
Wattage Equivalent (W)	56
Voltage (V)	220 - 240 V
Dimmable	yes
Power Factor	0.9
Operating Frequency (Hz)	50-60
<b>Geometric Data</b>	
Length (mm)	56.6
Diameter (in mm)	49.9
Weight (g)	65
<b>Photometric Data</b>	
Luminous Flux 90° Cone (lm)	390
CRI	80
CCT (K)	2700
Luminous Intensity (cd)	720
Beam Angle (°)	36
Luminous Efficacy (lm/W)	53
Lifetime (hrs)	35,000
Switching Cycle	60,000

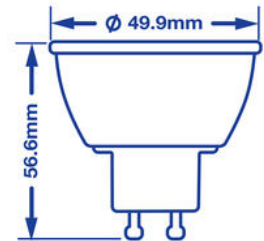

02/07/2014


### Photometric Diagrams

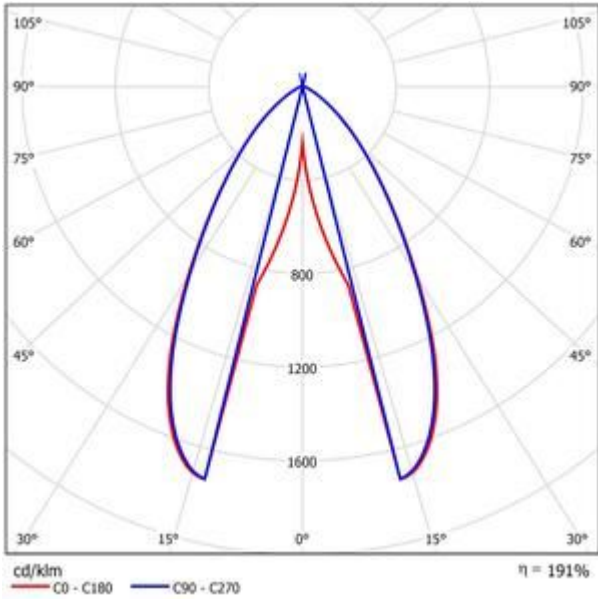

Distance [m]	Cone Diameter [m]		Illuminance [lx]		
0.5	0.63	0.63	E(0°)	400	
			E(C90)	32.1°	874
			E(C0)	32.4°	863
1.0	1.25	1.27	E(0°)	100	
			E(C90)	32.1°	219
			E(C0)	32.4°	216
1.5	1.88	1.90	E(0°)	44	
			E(C90)	32.1°	97
			E(C0)	32.4°	96
2.0	2.51	2.54	E(0°)	25	
			E(C90)	32.1°	55
			E(C0)	32.4°	54
2.5	3.14	3.17	E(0°)	16	
			E(C90)	32.1°	35
			E(C0)	32.4°	35
3.0	3.76	3.81	E(0°)	11	
			E(C90)	32.1°	24
			E(C0)	32.4°	24

Distance [m]      Cone Diameter [m]      Illuminance [lx]  
 — C0 - C180 (Half-value Angle: 64.8°)  
 — C90 - C270 (Half-value Angle: 64.2°)

### Energy Rating

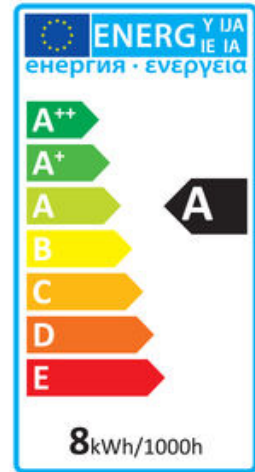

### Technical Packaging Details

**Barcode**

023942522348

**EAN 128**

(02)00023942522348(37)10(91)162

**EAN 14**

50023942522343

**Pack Dimensions (HxWxL)**

H 65 x W 50 x L 50

**Pack Weight**

81

**MOQ**

10

**Carton Dimensions (HxWxL)**

H 58 x W 135 x L 287

**Cartons/Pallet**

256

**Layers/Pallet**

16

**Units/Pallet**

2560

02/07/2014