

#4139- Grey 4 Core Standard Microphone Cable, 50m



Part NO: #4139

Product Code: RGW-1878

Product Description

Application:

Multi-conductor-audio,control.& Instrumentation Cables.

Multi-construction

4 Cores

Construction

4 Cores	Tinned Copper
Construction	T0.12±0.008×14
Stranded Dia.(mm)	0.52
Insulation	PVC
Thickness	0.39
Insulation Dia.(+/-0.05mm)	1.3 x 4C Twist
Insulation Color	Red, White, Blue & Green
Cotton Paper	≥115%
Spiral Braid	Tinned Copper
Construction	T0.15 x 48
Jacket	PVC
Thickness(mm)	0.85
Dia.(+/-0.15mm)	4.70
Jacket Color	Grey

Marking


According to customer

PACKAGING

50M/Reel

100M/Reel

Design

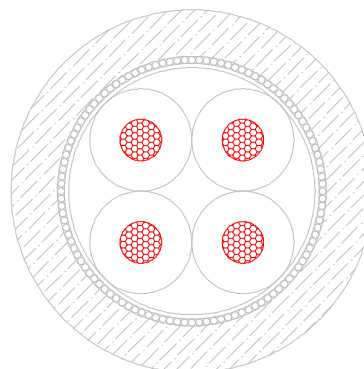

Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<84.7
Rated Temperature(°C)	-20 to +80
Rated Voltage(V)	1000
20°C Insulation Resistance(M Ω .KM)	> 200
Capacitance to Screen @ 1 KHz (Pf/m)	120

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls (PBB)	Forbidden	GC/MS	/
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	/

Revision History

A0-1

Date: 2013-03-06

Page: 1 / 1