



Capsuleline

Capsuleline 100W GY6.35 12V CL 4000h 1CT

Single-ended low-voltage halogen capsule giving crisp white halogen light. Compact shape, crisp white light. Low-voltage halogen capsule. Ideal solution for small decorative luminaires. UV-block glass and low-pressure filling allow usage without cover glass. The compact Capsuleline delivers crisp white light over a long lifetime.

Product data

• General Characteristics

Philips Code	13100
Cap-Base	GY6.35
Cap-Base Information	15
Bulb	T4 [T4: .434 inch / 11mm]
Bulb Finish	Clear
Operating Position	any [Any or Universal (U)]
Rated Lifetime (hours)	4000 hr
Rated Lifetime (years)	4 an

• Light Technical Characteristics

Color Rendering Index	100 Ra8
Color Temperature	3000 K
Color Temperature Technical	3000 K
Luminous flux lamp	2200 Lm
Rated Luminous Flux	1850 Lm
Luminous Efficacy Lamp	22 Lm/W

• Electrical Characteristics

Rated Wattage	100 W
Lamp Wattage	100 W
Lamp Wattage Technical	100 W
Voltage	12 V
Lamp Current	8.33 A
Dimmable	Yes
Starting Time	0.01 (max) s
Warm-up Time to 60% Light Outp	instant full light

• Environmental Characteristics

Mercury (Hg) Content	0.0 mg
----------------------	--------

• Measuring Conditions

Switching cycle	16000X
-----------------	--------

• Luminaire Design Requirements

Pinch Temperature	350 (max) C
Bulb Temperature	900 (max) C

• Product Dimensions

Overall Length C	44 (max) mm
Diameter D	12 (max) mm
Overall Width E	12 (min) mm
Light Center Length L	30 mm
Overall Height H	44 (min) mm

• Product Data

Order code	924040017101
Full product code	924040017101
Full product name	Capsuleline 100W GY6.35 12V CL 4000h 1CT
Order product name	Caps 100W GY6.35 12V CL 4000h 1CT/10X10F
Pieces per pack	1
Packing configuration	10X10F
Packs per outerbox	100
Bar code on pack - EAN1	8711500402158

PHILIPS


sense and simplicity

Capsuleline

Bar code on intermediate packing - EAN2 8711500417015
Bar code on outerbox - EAN3 8711500425713

Logistic code(s) - 12NC 924040017101
ILCOS code HSG/C/UB-100-12-GY6.35
Net weight per piece 2.300 gr

Dimensional drawing

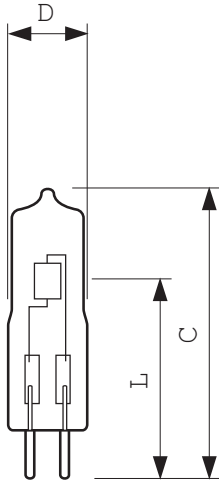

Capsuleline 100W GY6.35 12V CL 4000h 1CT

Product	C (Max)	D (Max)	L (Norm)
CAP SU 13100 100W GY6.35 12V CL	44	12	30



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, December 28
data subject to change