


Deep groove ball bearings, single row, unsealed

Product information



Tolerances , see also text
Radial internal clearance , see also text
Recommended fits
Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit	Speed ratings		Mass	Designation
d	D	B	dynamic	static	P_u	Reference speed	Limiting speed		
mm			kN	C_0	kN	r/min		kg	* - SKF Explorer bearing
60	110	22	55,3	36	1,53	13000	8000	0,78	6212 *

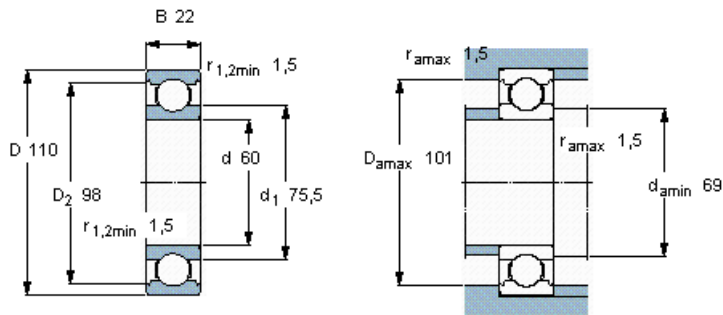

Calculation factors

k_f 0,025
 f_0 14