

Datasheet

RS Tinned Copper Test Lead Wire 1 mm² CSA 500 V 19 A Red Silicone Single Core, 332 Strands 5m

Stock number: 748-1964



Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

Single

Cable Construction

Conductor	Tinned Copper
Cross section	1.0mm ²
Construction(±0.003mm)	T0.08× 199
Standard Dia.	1.26
Jacket	silicone rubber
Thickness	1.0
Jacket Dia.(mm)	3.30±0.15
Color	Red: Black;


Marking

No Printing

PACKAGING

5M/ plastic Bag

Suitable pieces/Box

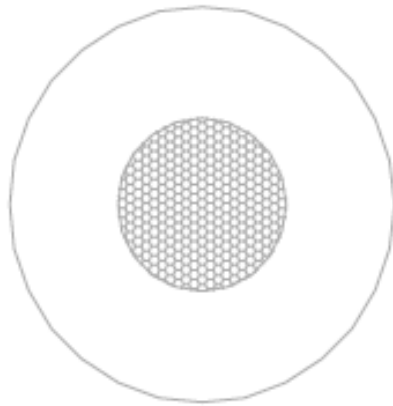

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	20
Min.Insulation DC Resistance at 20 °C (M Ω *Km)	>500
Rated Temperature(°C)	-55~+200
Rated Voltage (V)	300/500