


• AT8/AT8K Series AdapToners

Models AT8 & AT8K

The AdapToner AT Series Modular Breakout Tone Generators make it simple to test any configuration of pairs in both 6 and 8 position modular jacks and plugs. Combining the features of our tone generators with a modular breakout adapter allows technicians to test continuity and polarity, send tone and supply talk battery to any pair in any configuration. With both a modular plug and jack on each unit, in-line testing is also made simple.

AT8 tone generators feature:

- 8 position "snag proof" modular plug
- 8 position jack with protective cover
- tone, continuity & talk battery supply using alligator clips
- selectable solid/warble tone signal
- quick reference guide with common wiring configurations
- weather resistant design

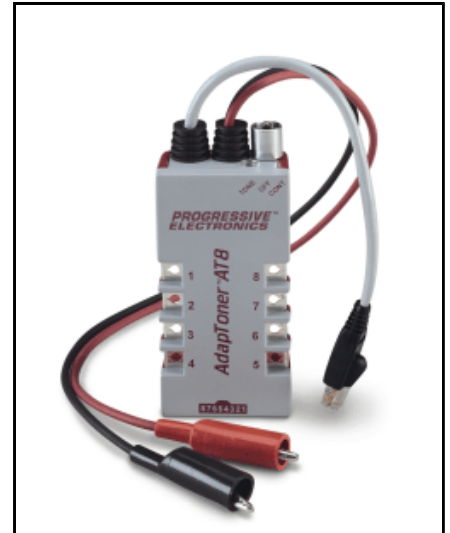

Specifications:

Power; one 9V battery, nominal life 50 hrs

Transmitter frequency; 900/1100 Hz alternating, 900 Hz constant

Transmitter power into 600 ohms; 7 dBm

Talk battery into 600 ohms; 6.5 VDC

Voltage protection at 600 ohms in CONT mode; 60 VDC (all units provide higher voltage protection in OFF/TONE modes)

High impact ABS case, 1.3 x 2 x 4.5", 24" test leads, 5.5 oz w/batt

AT8K Tone & Probe Kit includes the AT8 and the 200EP Inductive Amplifier in a 700C Carrying Case

