

EM 237



Euromas II
 Enclosure, polycarbonate

Order no.: 62237000

Colour of enclosure group

Light grey, similar to RAL 7035; special colours on request


Protection class

IP 65/DIN EN 60529; higher ingress protection on request

Enclosure material

ABS, PC (UV stabilised); seal made of CR; UL 94 V0 types on request; for details see Technical Information

Scope of delivery: Lid and base, self-tapping coarse-pitch thread lid screws made of V2A

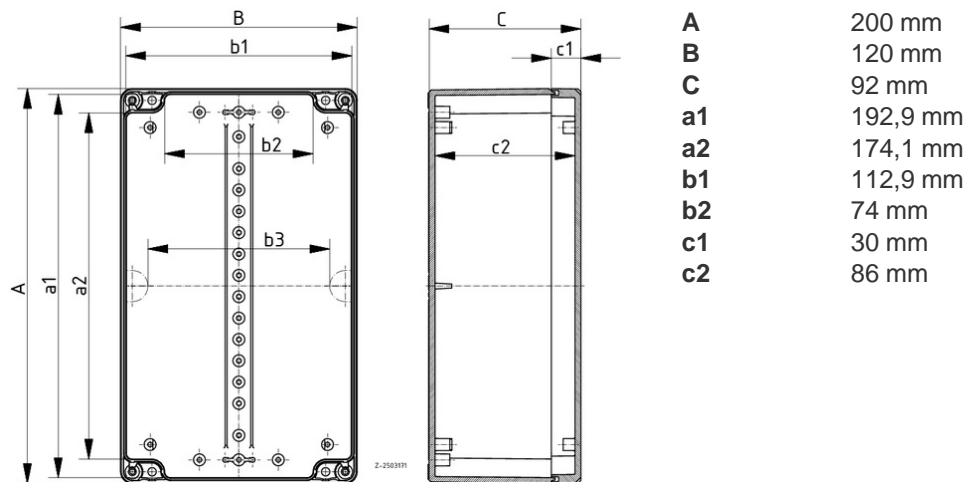

Technical drawings

Catalogue drawing in DXF format:

[62237000_EM-237.dxf](#) (1.0 MB)

3D product data in STEP format:

[Registration necessary](#)

Basic drawing for processing work:

[62237000_EM-237-G.dxf](#) (462 KB)

Catalogue drawing in PDF format:

[62237000_EM-237.pdf](#) (109 KB)

Chapter download

[Euromas II_GB.pdf](#) (362 KB)

Accessories



Rubber feet, self-adhesive

22009000 [GF](#)

Polyurethane, 65-75 Shore Black



Wall brackets, screw-on at rear

22010000 [EM-WL](#)



Screw covers


22080000 [EM-SA](#)



Mounting panels, laminated paper

22000700 [M](#)

For EM/ET 221, EM/ET 237, M/T 221, M/T 237

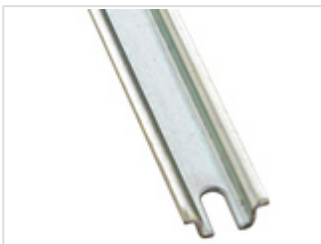

DIN rail acc. to DIN EN 60715 TH 15

22151901 [TS 15](#)

For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, BCD 200, B 2213..



DIN rail acc. to DIN EN 60715 G 32

22321901 [TS 32](#)

For EM/ET 214, EM/ET 221-223, EM/ET 232, EM/ET 237, B 22130.



DIN rail acc. to DIN EN 60715 TH 35

22351901 [TS 35](#)

For EM/ET 214, EM/ET 221-223, EM/ET 232,

EM/ET 237, BCD 200, B 2213..



* = Available on request