

64196

OSRAM ORIGINAL LINE | Halogen headlight lamps for trucks



Areas of application

- Headlight

Product benefits

- OEM Quality
- Wide product range
- Reliable quality

Product features

- Original spare parts

Technical data

Electrical data


Power input	85 / 80 W ¹⁾
Nominal voltage	24 V
Test voltage	28.0 V

¹⁾ Maximum

Photometrical data

Color temperature	3200 K
Luminous flux	1900/1200 lm
Luminous flux tolerance	±15 / ±15 %

Dimensions & weight

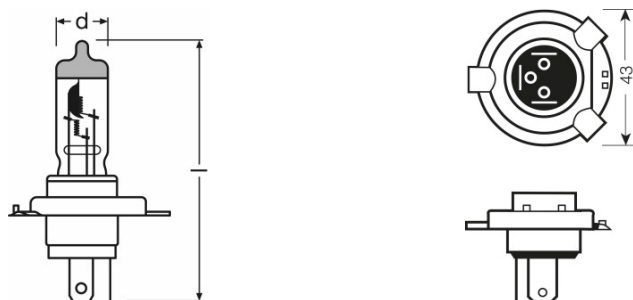

Length	82.0 mm
Product weight	24.20 g

Lifespan

Lifespan B3	170 / 350 h ¹⁾
Lifespan Tc	400 / 800 h ¹⁾

¹⁾ Filament 1 / Filament 2

Additional product data

Base (standard designation)	P43t
-----------------------------	------

Certificates & standards

ECE category	H4
--------------	----

Country specific categorizations

Order reference	64196 75/70W 24
-----------------	-----------------

Product datasheet

Country specific information

Product code	METEL code	SEG number	STK number	UK Org
4050300016542	OSRA64196	8328060	4739964	-

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300016542	64196	Folding carton box 1	47 mm x 47 mm x 70 mm	0.15 dm ³	31.00 g
4050300212272	64196	Bundle 10	239 mm x 70 mm x 96 mm	1.61 dm ³	312.00 g
4050300212289	64196	Shipping carton box 100	245 mm x 156 mm x 485 mm	18.54 dm ³	3570.00 g
4050300925868	64196	Blister 1	95 mm x 61 mm x 135 mm	0.78 dm ³	36.60 g
4008321142849	64196	Shipping carton box 10	119 mm x 145 mm x 335 mm	5.78 dm ³	466.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.