


## Magnetic Ballasts for HID Lamps

### Magnetic Ballast Electrical Data

Lamp Watts (W)	250
Lamp Current (A)	3.00
Input Voltage at 50Hz	230/240
Circuit Watts (W)	286
Running Current (A)	1.32
Delta T (°C)	70/75
tw (°C)	140
Thermal cut out °C (± 5°C)	160
Capacitor Value (µf)	30
Capacitor Voltage (V)	250
Energy Efficiency Index (EEI)	A3

### Physical Data

Dimensions (LxWxH mm)	167x87x72
Fixings (mm)	150-160
Weight (kg)	3.6

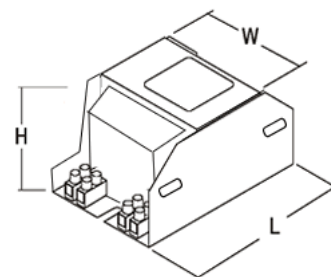

Ballast Diagram

Revision: 15-07-2013

\*\*See page 2 for product notes\*\*



Product Code: HSA25223221

## Magnetic Ballasts for HID Lamps

### Notes:

Additional fixings 70x143-157mm and side fixings 136-154mm