
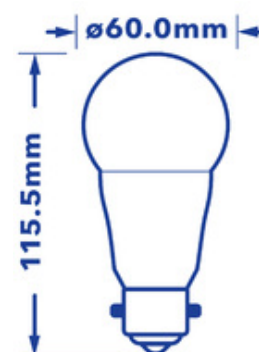


Verbatim LED Classic A B22 9W 2700K Warm White 810 LM


- B22 Socket
- 220 - 240 V Voltage
- 20,000 hours Lifetime
- 85% Energy Saving
- Luminous Flux: 810
- Equivalent to 60W incandescent bulb

Product Number	52612
General Data	
Lamp Socket	B22
Electric Data	
Wattage (W)	9
Wattage Equivalent (W)	60
Voltage (V)	220 - 240 V
Dimmable	no
Power Factor	0.90
Operating Frequency (Hz)	50-60
Geometric Data	
Length (mm)	115.5
Diameter (in mm)	60
Weight (g)	76
Photometric Data	
Luminous Flux (lm)	810
CRI	≥ 80
CCT (K)	2700
Beam Angle (°)	220
Luminous Efficacy (lm/W)	90
Lifetime (hrs)	20,000
Switching Cycle	100,000

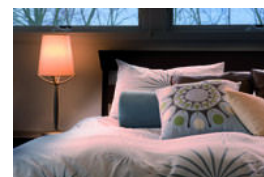

16/07/2014

Energy Rating

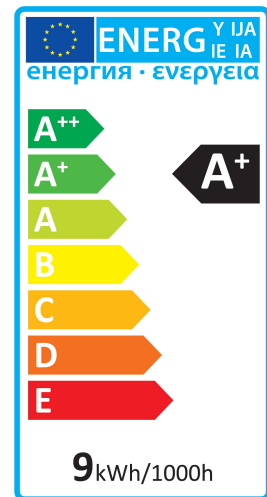Technical Packaging
Details**Barcode**

023942526124

EAN 128

(02)00023942526124(37)04(91)204

EAN 14

50023942526129

Pack Dimensions(HxWxL)

178 x 118 x 61 (mm)

MOQ

4

Carton Dimensions (HxWxL)

195 x 144 x 253 (mm)

Cartons/Pallet

80

Layers/Pallet

4

Units/Pallet

320

16/07/2014