



No.390, Yong He Road,
Shanghai 200072, China

TECHNICAL DATA SHEET CABLE ASSEMBLY

PART NUMBER :R284C0351047

Issue : NA

Date : NA


Customer :

Specification : NA

Issue : NA

Date : N/A

All dimensions are in mm

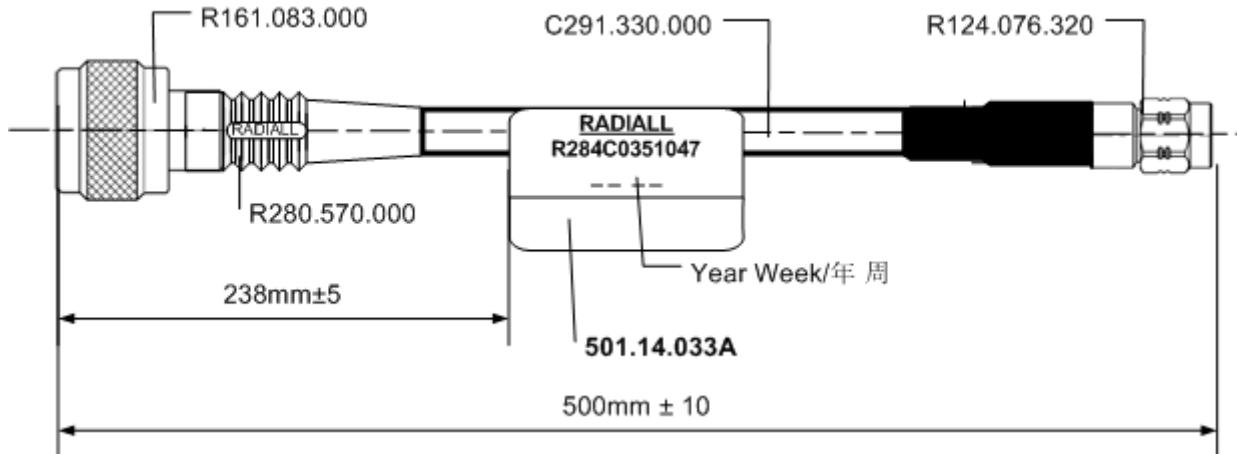

Connectors designation :

Connector 1 : N straight plug full crimp type
cable 5/50 D (R161.083.000)

Connector 2 : SMA straight plug full crimp type
cable 5/50 D (R124.076.320)

Cable designation :

Flexible Cable 5/50D (RG223)
C291.330.000
Lg: 500 mm

Nominal length :

Cable colour :

Black

Outer diameter :

5.38 mm

Accessories :

Plastic Boots (R280.570.000)

ELECTRICAL CHARACTERISTICS :

High Frequency

Characteristic impedance : 50 ± 2 Ohms

Frequency range : DC-11GHz

Insertion Loss : 0.58 dB max @ 3GHz & 20°C

VSWR. : TBT

Low Frequency

Insulation Resistance : 5000 MOhms min

Voltage Rating : 335 Veff max

MECHANICAL CHARACTERISTICS :

Recommend min. bend radius : 25 mm

Cable crush resistance : NA

Life (connectors) : 100 cycles

ENVIRONMENTAL CHARACTERISTICS :

Operating temperature range : -40° C to +85° C

Remark : NA

Attachment : R161.083.000-TDS , R124.076.320-TDS

C291.330.000 (RG223)-TDS

Cable Assembly is RoHS compliant.

CUSTOMER'S APPROVAL

Service or
Company's stamp

Name
Date

Jacob	A	2007-6-11	Creation	Willy
Name	Issue	Date	Modification	Checked by