

Internal Hexagon Head




Description

Shuts off a circuit end.
 Assembly with a hexagonal wrench.

Technical Specifications

Maximum Working Pressure	250 bar 25 Mpa 3626 psi
Working temperature	-40 to 150 °C -40 to 302 °F 233 to 423 °K
Body	Brass

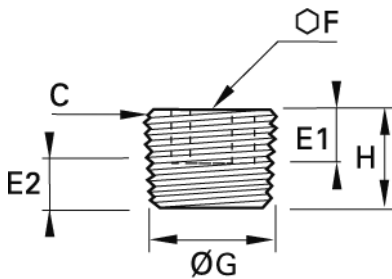

Dimensions

C	E1 (MM)	E2mini(MM)	E2mini (MM)	F (MM)	ØG (MM)	H (mm)	Weight (kg)
R1/8	6	3.1	4.9	5	9.73	8	0.003