

Datasheet

RS 100m 2 Core Multicore Speaker Cable, 2.5 mm² CSA PVC Sheath Material, PVC Insulation 300 V

RS Stock No. 749-2608



Part NO: RGW-1594

Product Code: 2 core loudspeaker cable

Product Description

Application:

For communication and signal control systems.

Reference Standard

Customer's sample spec.and the general standard


Multi-construction

2

Cable Construction

Conductor	Bare Copper
Area	2.5mm ²
Construction	0.15±0.005x129
Insulation	PVC
Thickness	0.5
Insulation Dia.(±0.1mm)	3.00
Insulation Color	Red; Black
Jacket	PVC
Thickness(mm)	0.65
Dia.(±0.2mm)	7.30
Jacket Color	Black
Marking	
2core x 2.5mm ² loudspeaker cable	ww/yy +Meter marking
PACKAGING	
100M/Reel	

Design

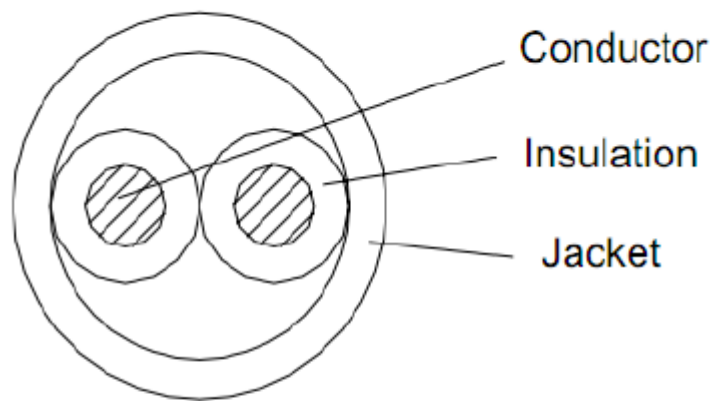

Electrical Characteristics

Max.Conductor DC Resistance at 20 °C (Ω /Km)	8.2
Min.Insulation DC Resistance at 20 °C ($M\Omega$ *Km)	>500
Rated Temperature(°C)	-20 to +60
Rated Voltage(V)	300