

## Datasheet

# RS Unshielded Test Lead Wire 2.5 mm<sup>2</sup> CSA 500 V Yellow Silicone Rubber Single Core, 462 Strands

5m

RS Stock No. 748-2005



### Product Description

#### Reference Standard

Customer's sample spec.and the general standard

#### Multi-construction

Single

### Cable Construction

<b>Conductor</b>	<b>Tinned Copper</b>
Cross section	2.5mm <sup>2</sup>
Construction(±0.003mm)	T0.08× 462
Standard Dia.	1.98
<b>Jacket</b>	<b>silicone rubber</b>
Thickness	0.95
Jacket Dia.(mm)	3.90±0.15
Color	Red: Black; Blue; Yellow Green


#### Marking

No Printing

#### PACKAGING

5M/ plastic Bag

Suitable pieces/Box

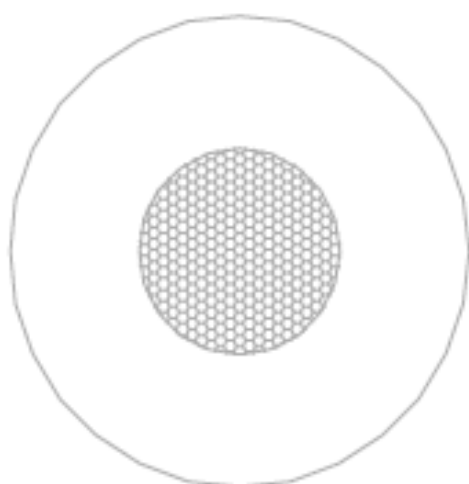

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C ( Ω /Km)	8.02
Min.Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-55~+200
Rated Voltage (V)	300/500