


# OTP\_80FP

1SCC390127M0202







Document no. 34OTP80F1 B

**OTPS80FP OTPL80FP OTPN80FP OTPE80FP OTPD80FP**

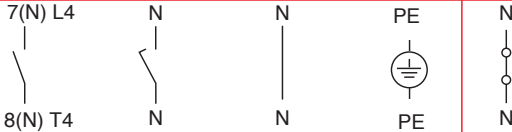


UL not completed  
CSA not completed  
OTPL80FP  
OTPD80FP

**UL** **US** IND.CONT.  
EQ 3E73  
General Use Ratings  
**600 VAC 80 A**  
Listed for use with  
OT63F3, OT80F3

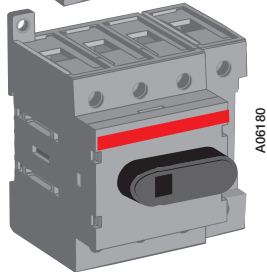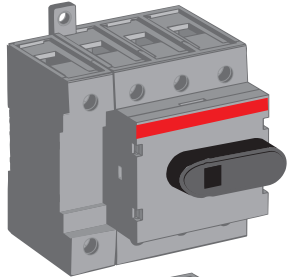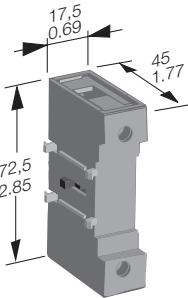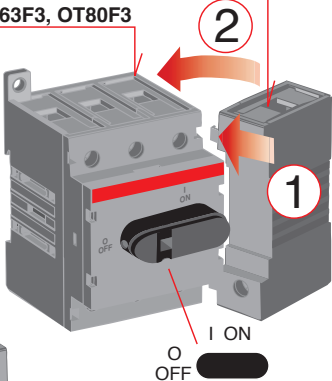
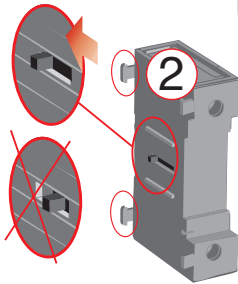
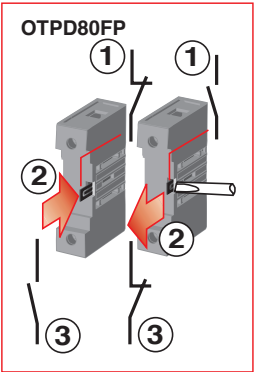


**!** Connect in the middle of the terminal clamp.

1,5...6 mm<sup>2</sup>  
14...10 AWG

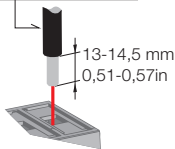

> 6...35 mm<sup>2</sup>  
> 10...4 AWG

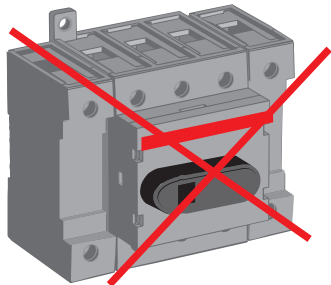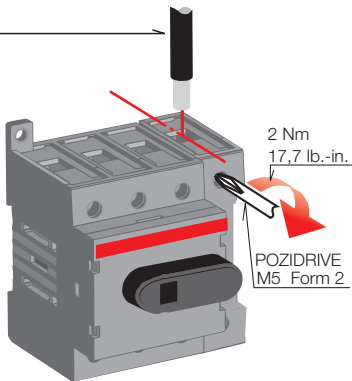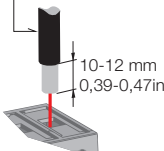

# OTP\_80FD

**OTPS80FD**

7(N) L4

8(N) T4

**OTPL80FD**

N

N

**OTPN80FD**

N

N


**OTPE80FD**

PE



PE


UL not completed  
CSA not completed  
OTPL80FD

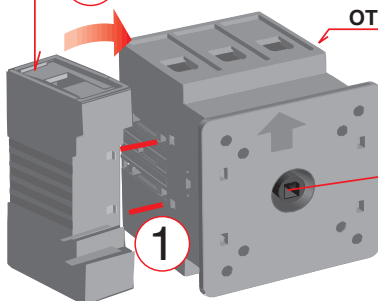



**OT63FT3, OT80FT3**

I ON

O OFF


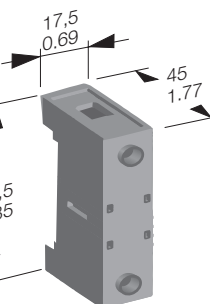


A06181

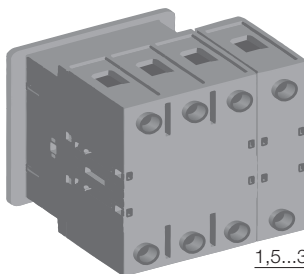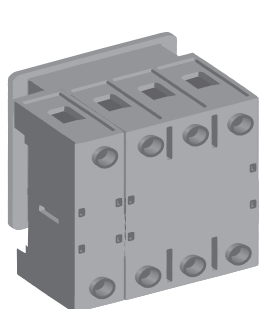

1,5...35 mm<sup>2</sup>  
14...4 AWG

10-12 mm  
0,39-0,47 in

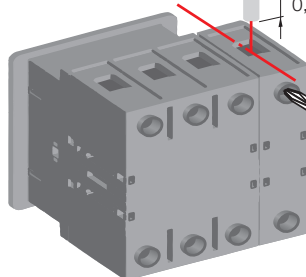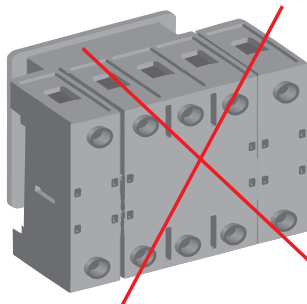

2 Nm  
17,7 lb.-in.

POZIDRIVE  
M5 Form 2

ABB Oy  
Breakers and Switches  
P.O.Box 622  
FI-65101 Vaasa, Finland

Telephone +358 10 22 11  
Telefax +358 10 224 5708

