


Data Sheet

Alarm 12C PVC

Cross Section:

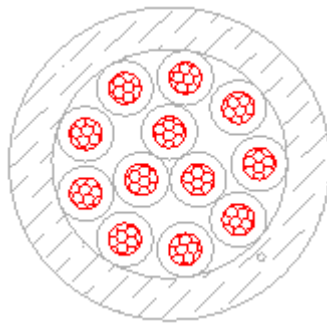

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V):300

Construction:

Conductor: Tinned Copper Claded Aluminium

Conductor Dia. (mm): TCCA0.19±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 1.00±0.08 x 12C

Nylon rip cord: 150D

Jacket: PVC

Outer Dia. (mm): 5.40±0.2

Colour:

The color of the insulation:

Red,Blue, Yellow,Black,White,Green,Brown,Orange
Grey,Pink,Violet,Light Green,

The jacket color: According to customer

Marking:

According to customer

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) :
<177

Min.Insulation DC Resistance at 20°C (MΩ
*KM) : >200